


**Frontpanel, skärmad, Sidogängad, 6 U, 84 HP,
2,5 mm, Al, främre anodiserad, bakre ledande**

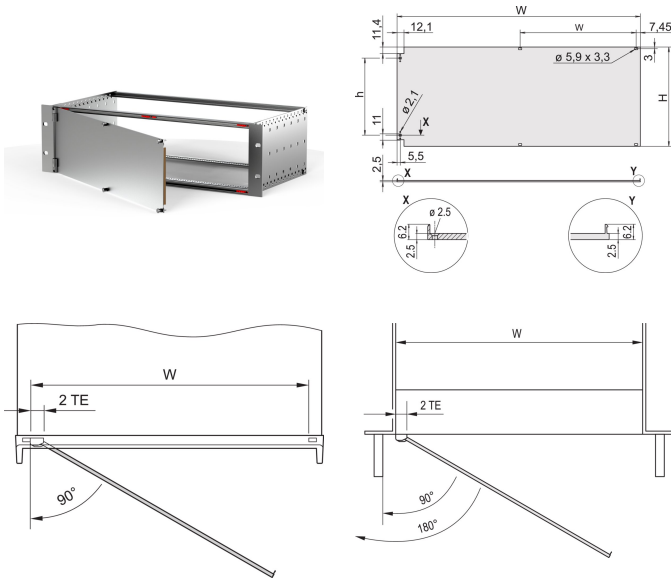

KATALOGNUMMER

20848-617

Frontpanel med EMC-packning i textil, sidomonterad enhet.

DESIGN

Frontpanel med textil EMC-packning

Möjliggör montering på horisontella skenor

Lämplig för underrack och lådor

Gångjärnen kan monteras på vänster eller höger sida



PRODUKTATTRIBUT

Rackhöjd: 6U

Antal i förpackningen: 1

Tillbehörstyp: Frontpanel

Montage: Gångjärnsförsedd, sida

Packningstyp: Textil

Främre finish: Anodiserad

Bakre finish: Ledande

Behandlade kanter: Nej

Djup (D): 2.5mm

EMC-skydd: Nej (kan eftermonteras)

Yta: Anodiserad; Passiverad


Höjd (H): 261.8mm

Material: Aluminium

Produkttyp: Frontpanel

Bredd (W): 426.4mm

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

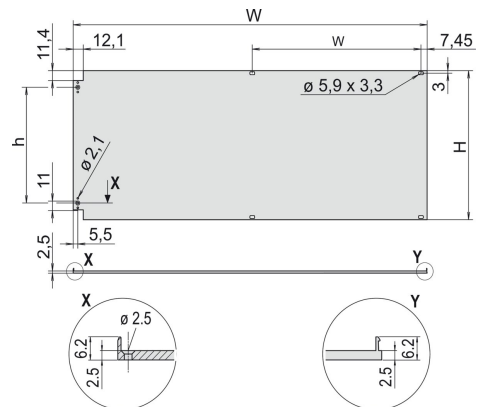

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplikering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Straubenhardt, Germany
 +49.7082.794.0
 Betschdorf, France
 +33.3.88.90.64.90
 Warsaw, Poland
 +48.22.209.98.35
 Assago, Italy
 +39.02.932.7141
 Chat with us:
nvent.com/schroff

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE