 



Sats med insticksmodul med IEL-handtag för bakre i/O, skärmad, Svart, 3 U, 8 HP

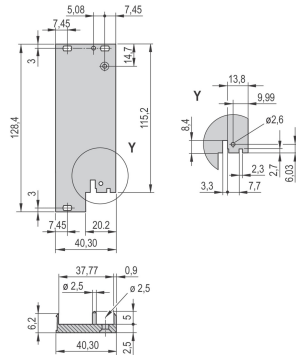

KATALOGNUMMER

20848-752

Plug-in-enhet, med svart handtag för IEL-insats/utsug, 3 U, bakre i/O-enhet. Den U-formade frontpanelen möjliggör avskärmning med textilpackning.

DESIGN

U-formad frontpanel för textilpackning

Lämplig för in- och extraktionskrafter upp till 700 N (per par)

Möjliggör installation av en mikrobrytare

Möjliggör installation av kodpinnar i enlighet med IEC 60297-3-103/ IEEE 1101,10



PRODUKTATTRIBUT

Rackbredd: 8HP

Antal i förpackningen: 1

Handtagstyp: IEL

Montage: Skruvas på baksida, IO

Packningstyp: Textil

Främre finish: Anodiserad

Bakre finish: Etsad

Behandlade kanter: Nej

Uppfyller: IEC 60297-3-102; IEEE 1101.10; IEC 60297-3-103; IEEE 1101.1/11

EMC-skydd: Ja

Yta: Anodiserad; Passiverad

Höjd (H): 128.4mm

Material: Aluminium

Produkttyp: Frontpanel

Rackhöjd: 3U

Typ: Frontpanel med handtag (PIU)


Bredd (W): 40.3mm

Nettovikt: 0.1kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

DIAGRAMS

3U

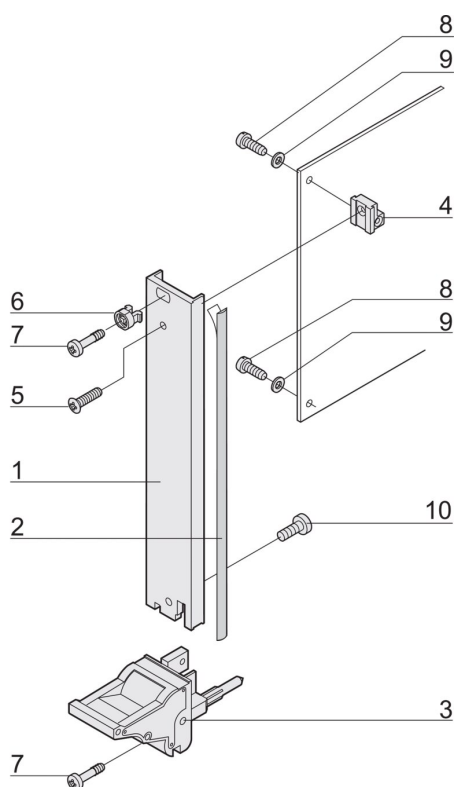

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE