


Frontpanel EMC textilskärningssats, -40... +85oC, 3 U; 10 st

KATALOGNUMMER

21102-853

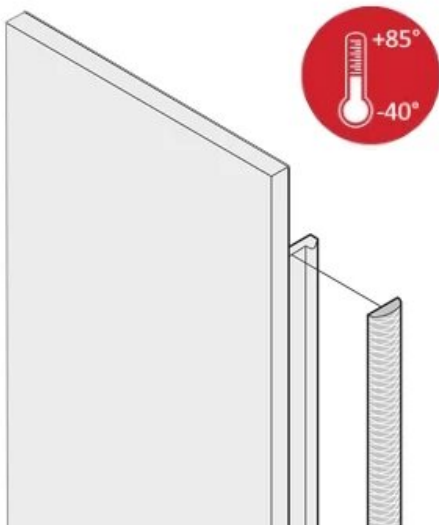

De textila EMC-packningarna sätts in i ett spår på höger sida av de U-formade frontpanelerna. Packningarna är limmade på frontpanelen. För ett utökat temperaturområde upp till +85C.

DESIGN

Textil EMC-packning fästs i sidled på frontpanelen eller i spåret på den högra profilen beroende på vad som är lämpligt.

Profiltätningen limmas på kontaktytan på 19-tumsfästet eller i den bakre vinkeln och skapar den ledande anslutningen till de U-formade frontpanelerna

Temperaturområde -40 C... +85 OC



PRODUKTATTRIBUT

Rackhöjd: 3U

Antal i förpackningen: 10

Djup (D): 1.62mm

Höjd (H): 97mm

Material: Termoplastiska elastomer

Produktfamilj: EuropacPRO; PropacPRO; RatiopacPRO, luft; PropacPRO; Plugin-enhet av ramtyp

Produkttyp: Avskärmningssats

Fungerar med: Underrack; Lådor; Frontpaneler


Bruttovikt: 0.053kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGARE PRODUKTINFORMATION

EMC-packningar (textil) krävs för skärmning av frontpanelerna.

DIAGRAMS

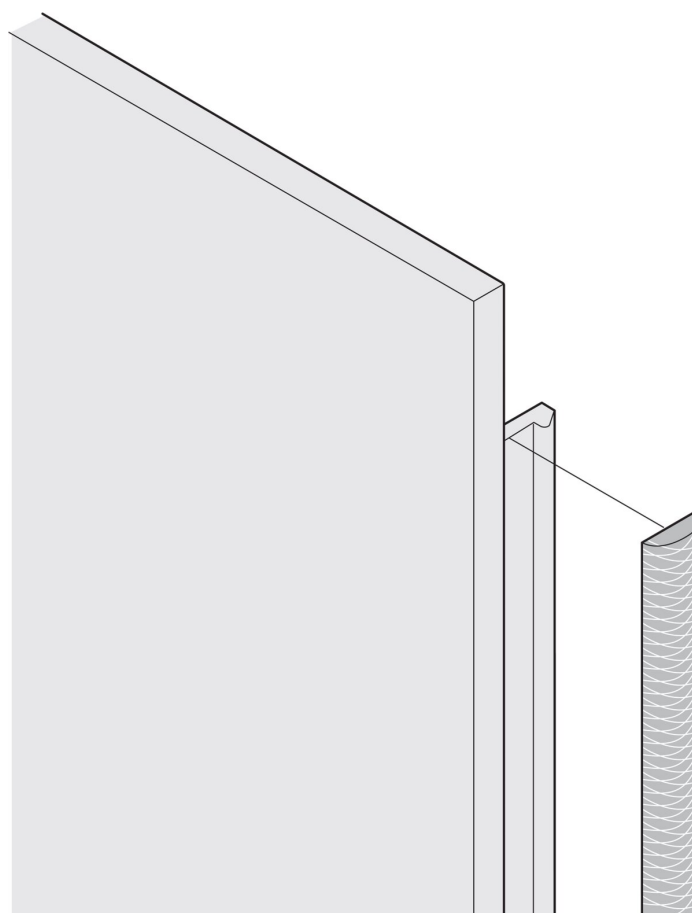

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE