


LHX+ vattenkontrollpaket

KATALOGNUMMER

23130-663

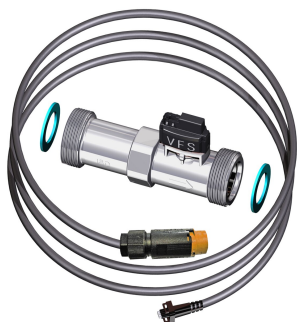

De rostfria rörinsatserna med ID 1 tum levereras med ett par ratiometriska sensorer för flytande kylvätska. Sensorerna ansluts direkt till RackChiller bakdörrsstyrenhet. Detta möjliggör övervakning av kylmedlets termiska egenskaper och kylprestanda samt ytterligare temperaturkontrollfunktioner.

DESIGN

Returgivare: Kylvätskeflöde och temperaturer

Gör det möjligt för styrenheten att modulera flödet baserat på returtemperaturen

Vattenkontrollenhet med vattenflöde, temperaturgivare

Båda rörinsatserna är tillverkade av rostfritt stål som kan skruvas fast i basplattan för att säkerställa hög EMC och IP

PRODUKTATTRIBUT

Produkttyp: Anslutningssats

Fungerar med: Varistar; Varistar CP

Bruttovikt: 0.576kg

Antal i förpackningen: 1

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGARE PRODUKTINFORMATION

LHX+-styrenhet krävs.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplisering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister,

egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE