

Styrskena med kodning IEEE ESD-klämma, inriktningssstift

KATALOGNUMMER


24560-256

ESD-klämman kan anslutas till styrskenas nyckel-/kodblock med kodning. Ger en ledande kontakt mellan inriktningssstiftet på kuverteringsmaskinens/utdragningshandtaget (IEL eller IET) och den horisontella skenan.

DESIGN

Monteras i den nedre och övre horisontella skenan

För inriktningssstift till IEEE; kan anslutas till styrskenorna med kodning och till nyckel-/kodblocket; ger ledande kontakt mellan styrsstiftet på kuverteringsmaskinens/utdragningshandtaget (IEL eller IET) och den horisontella skenan

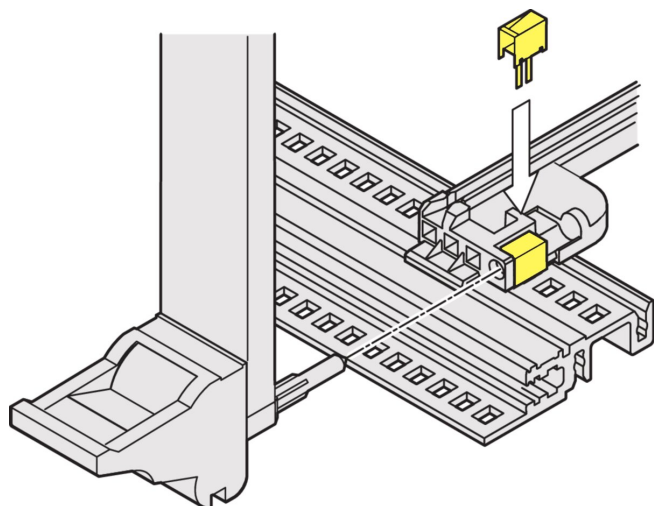

PRODUKTATTRIBUT

Produkttyp: Styrskena

Produktfamilj: EuropacPRO; RatiopacPRO; RatiopacPRO, luft; CompacPRO; PropacPRO; MultipacPRO; Inpac

Typ: ESD-klämma

Fungerar med: Styrskenor; Lådor; Chassi

Material: Stål

Antal i förpackningen: 50

Yta: Tennpläterad

Bruttovikt: 0.024kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE