

Airbender, kortguideinsats, 70P blockering, 4 HP, 160 mm, sats med 10 delar

KATALOGNUMMER

24563-040

nVent SCHROFFS inlägg förbättrar kylningseffektiviteten med upp till 85 % per plats genom att balansera luftflödet i miljöer med blandad impedans. Den är enkel att installera, minskar fläktljudet och förbättrar systemets övergripande prestanda.

DESIGN


Airbender-kortstyrningsinsatser förbättrar kylningseffektiviteten i elektroniska system med upp till 85 % per 4 hk-plats genom att balansera luftflödet i miljöer med blandad luftimpedans

70 % blockering: Airbender introducerar ytterligare luftimpedans i slitsar med mindre kritiska komponenter, omdirigerar luftflödet till mer sårbara zoner och säkerställer bättre kylningsresultat för alla kort

Enkel installation: Fäst Airbender i nVent SCHROFFS plastkortstyrningar och fäst den med en skruv som tillval

Främjar minskad bullerutveckling från fläktarna genom att hålla dem på en effektiv driftspunkt

Air Bender och CassettePRO kan inte användas tillsammans i samma fack.

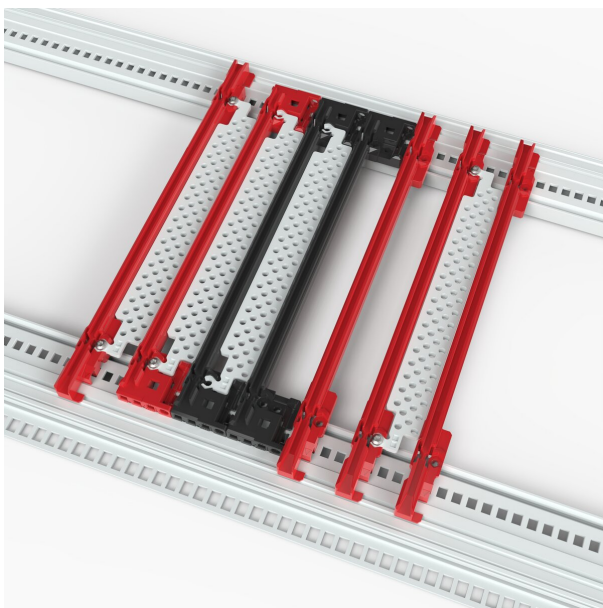

PRODUKTATTRIBUT

Produkttyp: Luftbaffel

Produktfamilj: EuropacPRO; RatiopacPRO; RatiopacPRO, luft; CompacPRO; PropacPRO; Inpac

Fungerar med: Underrack; Lådor; System

Rackbredd: 4HP

Djup: 160mm

Material: Polykarbonat

Antal i förpackningen: 10

Färg: Grå

Uppfyller: EN 45545-2; UL® 94V-0

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGARE PRODUKTINFORMATION

Airbenders med olika blockeringsnivåer finns tillgängliga på begäran.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE