

EuropacPRO 19-tums subracksats för bakplan, skärmad, CompactPCI, 3 U, 275 mm



KATALOGNUMMER

24563-157

EMC-skärmat underrack för montering på bakplan, för CPCI-tillämpningar.

DESIGN

Subrack med sidopanel typ F ("flexibel") för CompactPCI plug-in-enheter med hög in- och uttagskraft

Aluminiumkonstruktion

Bakre horisontell skena för montering på bakplan med isoleringslist

Inre och yttre mått i enlighet med: IEC 60297-3-100, -101, - 102, -103, -104, IEEE 1101,1, IEEE 1101.10/11

Modifieringar som utskärningar, olika ytbehandlingar eller dimensioner finns tillgängliga

EMC på cirka 40 dB vid 1 GHz, 30 dB vid 2 GHz, förutsatt att fronten är täckt med skärmade frontpaneler, testning enligt VG 95373 del 15

Levereras som platsbesparande platt-pack

IP 20, i enlighet med IEC 60529

Horisontell rälstyp "tung"



PRODUKTATTRIBUT

Rackhöjd: 3U

Djup (D): 275mm

Bakre I/O: Ja

Antal i förpackningen: 1

För montering: Bakplan

Kortdjup: 80mm; 160mm

Packningstyp: Textil

Handtag ingår: Nej

Montage: Rack

Uppfyller: IEC 60297-3-103; IEEE 1101.10; IEEE 1101.11

EMC-skydd: Ja

Yta: Anodiserad; Passiverad

Material: Aluminium

Produkttyp: Underrack/chassi

Rackbredd: 84HP

Statisk belastning: 11kg


Nettovikt: 2.71kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGARE PRODUKTINFORMATION

Individuell konfiguration: Brett utbud av varianter i höjd, bredd och djup; styrskenor för en mängd olika tillämpningar; interiöralternativ; tillbehör och monteringsmaterial.

DIAGRAMS

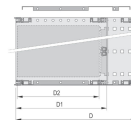

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation,

missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE