
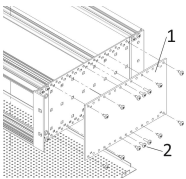


EuropacPRO Advanced EMC sidopannelskydd, 4U, 295 mm

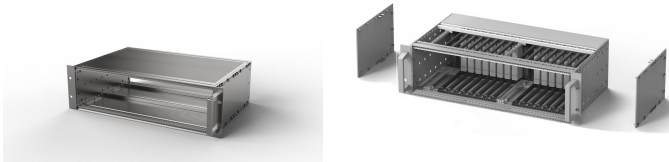

KATALOGNUMMER

24563-267

Aluminiumsidopanel 3 mm för att öka EMC-skärmningseffekten hos understället genom att täcka de utskärningar som inte behövs.

DESIGN

Sidopannelskydd för ökad lateral RF-avskärmning

Monteras på utsidan av standardsidopanelen

Monteringsmaterial ingår



PRODUKTATTRIBUT

Rackhöjd: 4U

Djup: 295mm

Antal i förpackningen: 2

EMC-skydd: Ja

Yta: Passiverad

Längd: 295mm

Material: Aluminium

Produktfamilj: EuropacPRO

Produkttyp: Sidopanel

Typ: Typ H

Fungerar med: Underrack

Paketenhet: Par

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGARE PRODUKTINFORMATION

Sidopanel och 19" fäste är tox-kallsvetsade ihop. Toxen = clinching teknik, utan ADD hjälpmedel. Detta sker med specialverktyg och högt tryck.

9 U-version tillgänglig på begäran.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE