

EuropacPRO 19-tums subracksats för bakplan, tung, eftermonterad avskärmning, med främre handtag, 3 U, 235 mm

KATALOGNUMMER

24567-162

Ej EMC-skärmd underrack för bakplansmontering, tung version med toxsvetsade sidopaneler och främre handtag.

DESIGN

Subrack med sidopanel typ H ("tung"), 19-tums fäste är ordentligt fastsatt på sidopanelen (tox-kallsvetsat)

Levereras som platsbesparande platt-pack

Bakre horisontell skena för montering på bakplan med isoleringslist

Horisontell rälstyp "tung"

Stöt- och vibrationstålighet upp till 5 g.


IP 20, i enlighet med IEC 60529

Stöt- och vibrationstestade enligt de tyska Bahnstandarderna BN 411002, BN 411003

Inre och yttre mått i enlighet med: IEC 60297-3-100, -101, IEEE 1101,1

Installerad belastning upp till 15 kg

Version med främre handtag

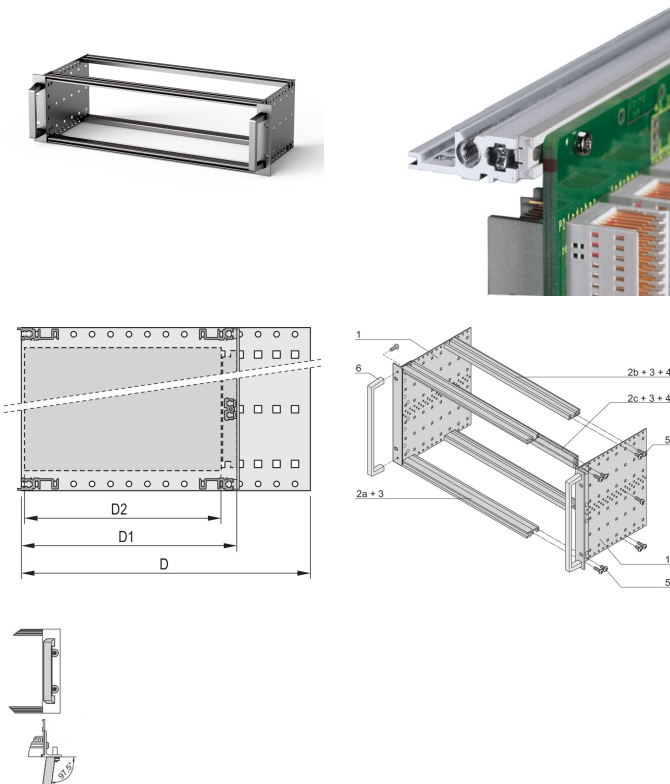

PRODUKTATTRIBUT

Rackhöjd: 3U

Djup: 235mm

Antal i förpackningen: 1

För montering: Bakplan

Kortdjup: 160mm; 220mm

Packningstyp: Rostfritt stål EMC

Stöt- och vibrationstolerans: 5g (force)

Handtag ingår: Ja

Montage: Rack

Uppfyller: IEC 60297-3-103

EMC-skydd: Nej

Yta: Anodiserad; Passiverad

Material: Aluminium

Produkttyp: Underrack/chassi

Rackbredd: 84HP

Statisk belastning: 15kg

Nettovikt: 1.425kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGARE PRODUKTINFORMATION

Individuell konfiguration: Brett utbud av varianter i höjd, bredd och djup; styrskenor för en mängd olika tillämpningar; interiöralternativ; tillbehör och monteringsmaterial.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE