

RatiopacPRO EMC Frontpanel, spår, Skärmad, 3 U, 42 HP, 2,5 mm, Al, främre anodiserad, bakre ledande

KATALOGNUMMER


24572-604

EMC-frontpanelen kan sättas in i speciella horisontella skenor med en höjd. Inga skruvar behövs för fixeringen. Designen gör det möjligt för användare att använda en frontfolie.

DESIGN

Montering kräver inga skruvar

Särskilda horisontella skenor täcker kanterna på frontpanelen (upptill och nedtill) och förhindrar att frontpanelen böjs

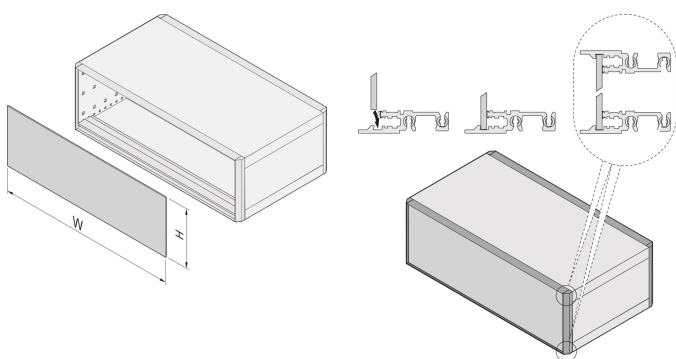

PRODUKTATTRIBUT

Rackhöjd: 3U

Rackbredd: 42HP

Tillbehörstyp: Frontpanel

Antal i förpackningen: 1

Främre finish: Anodiserad

Bakre finish: Ledande

Behandlade kanter: Nej

Djup: 2.5mm

Yta: Anodiserad; Passiverad

Höjd: 128.4mm

Material: Aluminium

Produkttyp: Frontpanel

Bredd: 213.2mm

Nettovikt: 0.55kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGARE PRODUKTINFORMATION

För att få ett skärmat hölje måste alla EMC-tätningar monteras (frontpanel/bakpanel ? Sidopanel; sidopanel ? täckplatta; frontpanel/bakpanel ? horisontell skena; horisontell skena ? horisontell skena).

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE