


Horisontell skena, bak, typ H-VT, tung, 1000 mm

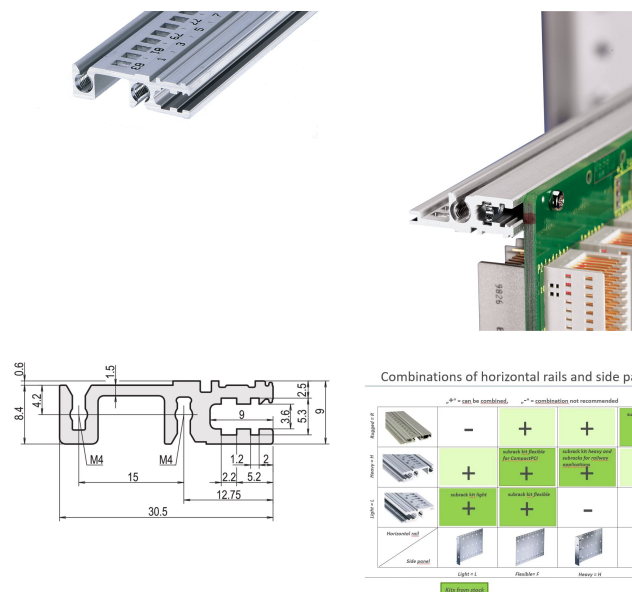

KATALOGNUMMER

34560-701

Den horisontella skenan, typ VT, möjliggör direkt montering av ett bakplan.

DESIGN

För direkt montering på bakplan

Montering upptill och nedtill

Infälld installation för höga mekaniska krav (H-VT)

Aluminium extrudering, anodiserad yta, ledande kontaktyta

Combinations of horizontal rails and side panels

„+“ = can be combined, „-“ = combination not recommended

	Horizontal rail	Horizontal rail with side panel	Horizontal rail with side panel (for high mechanical strength)	Horizontal rail with side panel (for high mechanical strength)
Horizontal rail	+	+	+	+
Horizontal rail with side panel	+	+	+	+
Horizontal rail with side panel (for high mechanical strength)	+	+	+	+
Horizontal rail with side panel (for high mechanical strength)	+	+	+	+

Side panel

Light rail

Standard rail

Heavy rail

Super rail



PRODUKTATTRIBUT

Rackbredd: 195HP

Antal i förpackningen: 1

Yta: Anodiserad

Längd: 1000mm

Material: Aluminium

Produktfamilj: EuropacPRO; RatiopacPRO; RatiopacPRO, luft; CompacPRO; PropacPRO

Produkttyp: Horisontell skena

Typ: Tungt, VT

Fungerar med: Underrack; Lådor

Nettovikt: 0.332kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGARE PRODUKTINFORMATION

Leverans sker i standardpaket. Priset är per enskild artikel.

Tänk på att leveranser kan utföras i angivna SPQ (SPQ, t.ex. 5 stycken, 10 stycken, 50 stycken, etc.). Olika orderkvantiteter (t.ex. 2 stycken) kan ändras till nästa möjliga leveranskvantitet = Standardförpackningskvantitet.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE