


# Horisontell skena bak, typ AB för bakre i/O-kortstyrningar, 42 hk

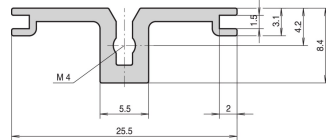

## KATALOGNUMMER

**34561-542**

Horisontell profilskena av aluminium av typen AB (AB = stöd), för bakre i/O-kortstyrningar, med anodiserad yta och ledande kontaktyta. Lämplig för RatiopacPRO/-AIR och EuropacPRO/-Rugged).

## DESIGN

För CompactPCI i området för bakre i/O

För 2 x 3 U expansion krävs 2 horisontella skenor av typ AB

Aluminiumextrudering, anodiserad yta, ledande kontaktyta, utan HP-märkning

Combinations of horizontal rails and side panels

|                 | Side panel not installed | Side panel installed | Side panel installed | Side panel installed |
|-----------------|--------------------------|----------------------|----------------------|----------------------|
| Horizontal rail | +                        | +                    | +                    | +                    |
| Vertical rail   | +                        | +                    | +                    | +                    |
| Horizontal rail | +                        | +                    | +                    | +                    |
| Vertical rail   | +                        | +                    | +                    | +                    |



## PRODUKTATTRIBUT

Rackbredd: 42HP

Antal i förpackningen: 1

Yta: Anodiserad

Längd: 218.44mm

Material: Aluminium

Produktfamilj: EuropacPRO; RatiopacPRO; RatiopacPRO, luft; CompacPRO; PropacPRO

Produkttyp: Horisontell skena

Typ: Typ, AB

Fungerar med: Underrack; Lådor

Bruttovikt: 0.038kg

\*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

## YTTERLIGARE PRODUKTINFORMATION

Leverans sker i standardpaket. Priset är per enskild artikel.

Tänk på att leveranser kan utföras i angivna SPQ (SPQ, t.ex. 5 stycken, 10 stycken, 50 stycken, etc.). Olika orderkvantiteter (t.ex. 2 stycken) kan ändras till nästa möjliga leveranskvantitet = Standardförpackningskvantitet.

## VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på [www.nvent.com](http://www.nvent.com) och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Vårt starka utbud av varumärken:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**