

EuropacPRO bakre huv för EMC-packning i rostfritt stål, 3 U, 84 HP

KATALOGNUMMER

34561-752

Den bakre huvan används som en avskärmad bakre gräns och kräver 60 mm utrymme. Om den bakre huvan används måste därför sidopanelens djup vara 60 mm större än brädans djup. Kontakt mellan den bakre huvan och de horisontella skenorna skapas av täckplattans kontaktlist i rostfritt stål. Därför behövs ingen ytterligare EMC-tätning. Den bakre huvan kan inte användas samtidigt som den bakre hörnprofilen.


DESIGN

Den bakre huvan används som en avskärmad bakre gräns. Den bakre huvan kräver 60 mm utrymme. Om den bakre huvan används måste därför sidopanelens djup vara 60 mm större än brädans djup. Exempel: För ett bräddjup på 160 mm används en sidopanel (med bakre huv) på 235 mm (175 mm + 60 mm)

Kontakt mellan den bakre huvan och de horisontella skenorna skapas av täckplattans kontaktlist i rostfritt stål. Därför behövs ingen ytterligare EMC-tätning

Den bakre huvan kan inte användas samtidigt som den bakre hörnprofilen

För EMC-skärmning beställer du EMC-packning för horisontell skena separat.

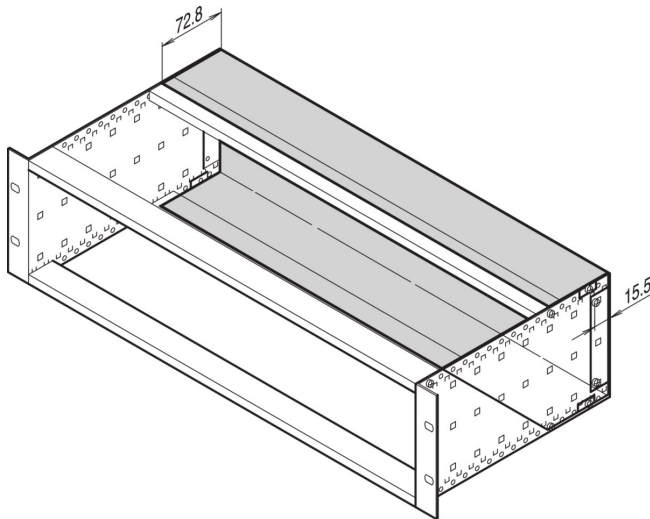

PRODUKTATTRIBUT

Rackhöjd: 3U

Rackbredd: 84HP

Antal i förpackningen: 1

Yta: Passiverad

Material: Aluminium

Produktfamilj: EuropacPRO

Produkttyp: Hölje

Typ: Bakre huv

Fungerar med: Underrack

Bruttovikt: 0.339kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGARE PRODUKTINFORMATION

Antal skruvar som krävs per bakre huv: 3 U-underställ 10 skruvar; 6 U-underställ 16 skruvar.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE