

Monteringsplatta för 19-tums fodral och Subrack, 84 HP, 220 mm kortlängd

KATALOGNUMMER

34562-752

Monteringsplatta för tunga komponenter eller egenutvecklade elektroniska enheter. Lämplig för RatiopacPRO/-AIR, CompacPRO och EuropacPRO.

Styrskenor av typ 4,4? Och typ förstärkta kan inte användas i kombination med en monteringsplatta. Övre/undre kåpa som ska sättas in i spåret på lampans (typ L) horisontella skenor kan inte användas i kombination med en monteringsplatta.


DESIGN

För montering av tunga komponenter

Monteringsplatta, full bredd: Monteringsplattan är lika bred som underrack/systemväska och är fäst vid sidopanelerna

Monteringsplatta, delbredd: Fästplattan för den partiella bredden som sitter fast på sidopanelen med hjälp av en monteringslist

Chassiplattformen kan inte kombineras med EMC topp-
/bottenkåpor

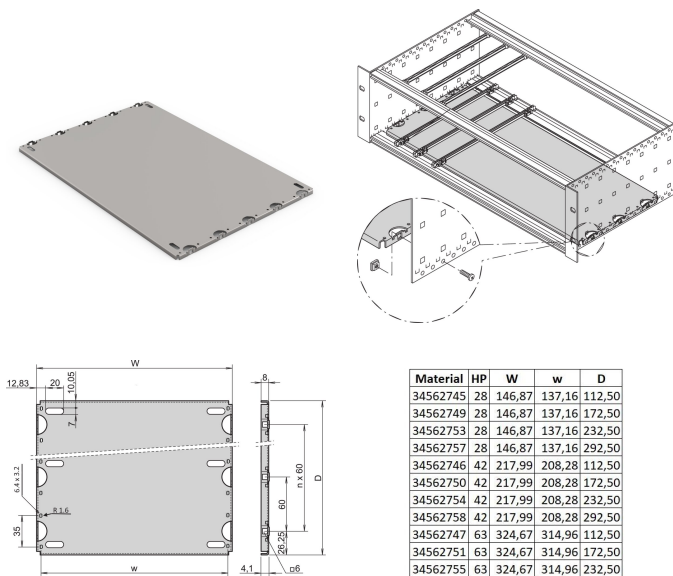

Material	HP	W	w	D
34562745	28	146,87	137,16	112,50
34562749	28	146,87	137,16	172,50
34562753	28	146,87	137,16	232,50
34562757	28	146,87	137,16	292,50
34562746	42	217,99	208,28	112,50
34562750	42	217,99	208,28	172,50
34562754	42	217,99	208,28	232,50
34562758	42	217,99	208,28	292,50
34562747	63	324,67	314,96	112,50
34562751	63	324,67	314,96	172,50
34562755	63	324,67	314,96	232,50
34562759	63	324,67	314,96	292,50
34562748	84	431,35	421,64	112,50
34562752	84	431,35	421,64	172,50
34562756	84	431,35	421,64	232,50
34562760	84	431,35	421,64	292,50
34562870	84	431,35	421,64	352,50
34562871	84	431,35	421,64	412,50

PRODUKTATTRIBUT

Rackbredd: 84HP

Antal i förpackningen: 1

Djup: 172.5mm

Material: Aluminium

Produktfamilij: EuropacPRO; CompacPRO; RatiopacPRO; PropacPRO

Produkttyp: Montageplåt

Bredd: 431.35mm

Fungerar med: Underrack

Nettovikt: 0.37kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

YTTERLIGARE PRODUKTINFORMATION

Beställ monteringssats för monteringsplatta separat.

Andra versioner på begäran.

Fästband krävs för delbredd, beställs separat.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE