

EuropacPRO monteringsplatta för användning med täckplatta, 42 hk, 160 mm kortlängd

KATALOGNUMMER

34563-002

Monteringsplatta för användning med täckplåtar för installation och fastsättning av tunga komponenter. Monteringsplattor med full bredd (lika breda som underrack eller systemväska) är fästa på sidopanelerna. De delbreddsfästplattorna är fästa på sidopanelen och den horisontella skenan med hjälp av en monteringsremsa.

Styrskenor av typ 4,4? Och typ förstärkta kan inte användas i kombination med en monteringsplatta. Övre/undre kåpa som ska sättas in i spåret på lampans (typ L) horisontella skenor kan inte användas i kombination med en monteringsplatta.

DESIGN


För montering och montering av tunga komponenter

Monteringsplatta, full bredd: Monteringsplattan är lika bred som underrack/systemväska och är fäst vid sidopanelerna

En styrskena kan monteras i första och sista spårläget

Förutom monteringsplattan kan EMC-täckplattor även monteras på understället

Styrskenor av typ 4,4 och "förstärkt" kan inte användas

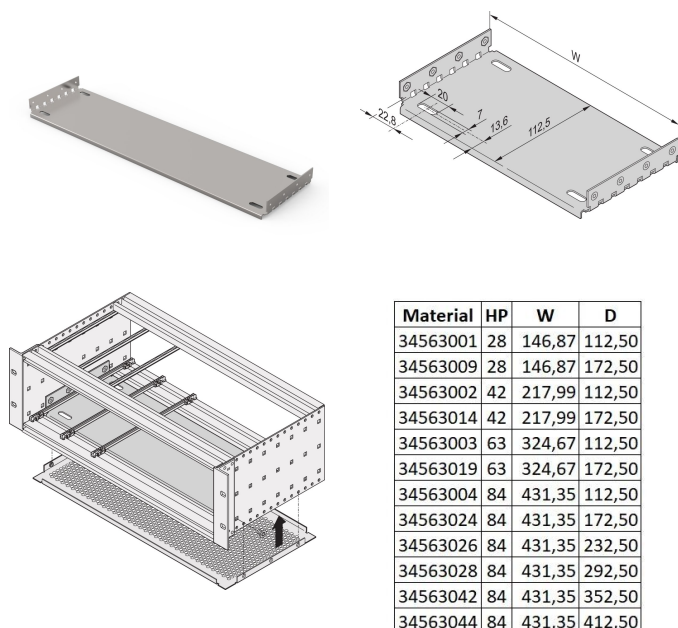

Material	HP	W	D
34563001	28	146,87	112,50
34563009	28	146,87	172,50
34563002	42	217,99	112,50
34563014	42	217,99	172,50
34563003	63	324,67	112,50
34563019	63	324,67	172,50
34563004	84	431,35	112,50
34563024	84	431,35	172,50
34563026	84	431,35	232,50
34563028	84	431,35	292,50
34563042	84	431,35	352,50
34563044	84	431,35	412,50

PRODUKTATTRIBUT

Rackbredd: 42HP

Antal i förpackningen: 1

Djup: 112.5mm

Material: Aluminium

Produktfamilj: EuropacPRO

Produkttyp: Montageplåt

Bredd: 217.99mm

Fungerar med: Underrack

Nettovikt: 0.125kg

*The price shown is the per piece price and does not include VAT. Depending on local conditions, packaging and freight charges might not be included. Where these charges should be part of the total price, they are included in the quote. The price given is a non-binding recommended retail price (RRP), which is the nVent list price. The final sales prices of local distributors may vary. Quotations requested or generated on SCHROFF.nVent.com are only valid for commercial customers (B2B). The lead time displayed above is an estimate for this item to be dispatched from an nVent Schroff facility. Transit delivery times are not included in this estimate, as transit time may vary, depending on delivery address, parcel dimensions, and other factors. Cut-outs and modifications placed in non-recommended areas ("collision detected") for configured products may be subject to additional engineering and/or design costs, which may increase initially quoted prices.

VARNING

nVent produkter ska installeras och användas endast så som anges i nVents bruksanvisning och utbildningsmaterial. Bruksanvisningar är tillgängliga på www.nvent.com och från din nVent kundtjänstrepresentant. Felaktig installation, missbruk, felapplicering eller annan brist i att helt följa nVents instruktioner och varningar kan orsaka att produkten brister, egendomsskador, allvarliga kroppsskador och dödsfall och/eller ogiltigförklara din garanti.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Vårt starka utbud av varumärken:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE