

Branch Line Restraint Pipe Attachment



功能

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe



Shear-off head helps ensure correct torque and simplifies inspection

完成: 电镀锌
材料: 钢



技术参数

物料号	订货号	NB/DN	外径 (OD)	杆尺寸 (RS)	高度 (H)	长度 (L)	宽度 (W)
CSBBRP0200EG	404480	50	60.3 mm	10, 12	100.3 mm	68.3mm	22.2 mm
CSBBRP0125EG	404478	32	42.2 mm	10, 12	82.6 mm	50mm	22.2 mm
CSBBRP0100EG	404477	25	33.4 mm	10, 12	73.7 mm	41.4mm	22.2 mm
CSBBRP0150EG	404479	40	48.3 mm	10, 12	88.9 mm	56.1mm	22.2 mm

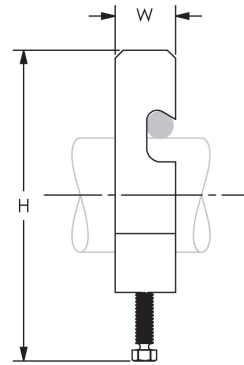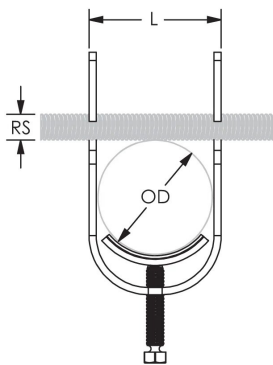

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

