

Branch Line Restraint Structure Attachment to Threaded Hole



功能

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to concrete anchors or structural attachments with female threads

Can be used for bolting through steel

完成: 电镀锌

材料: 钢



技术参数

Table 1/2


物料号	订货号	杆尺寸 (RS)	高度 (H)	长度 (L)	宽度 (W)	螺钉直径 (Sc)
CSBBRS3EG		0.375, 0.5	28.2 mm	40.4mm	26.9 mm	0.375
CSBBRS3MEG	402241	10, 12	28.2 mm	40.4mm	26.9 mm	10

Table 2/2

物料号	订货号	螺钉长度 (L)	认证
CSBBRS3EG		19mm	OSHPD, UL, FM Approved, Seismic
CSBBRS3MEG	402241	19mm	UL, FM Approved, Seismic, AON Fire Protection, Rigid Seismic

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

图

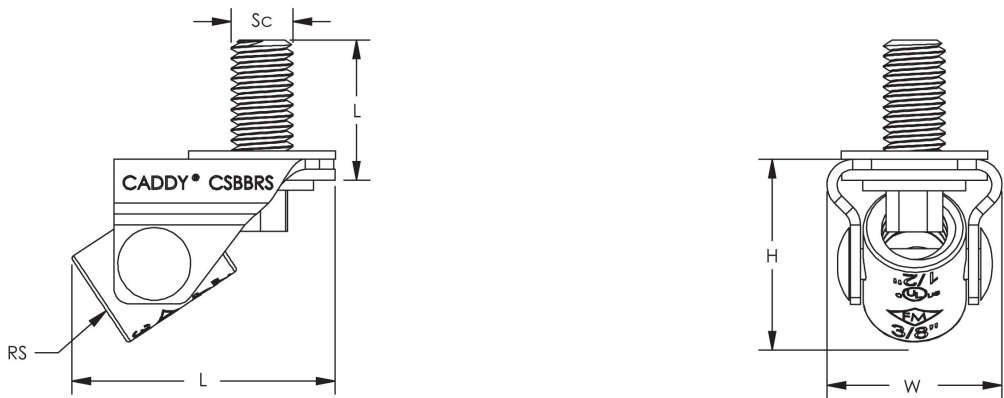

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

