

nVent CADDY Macrofix Plus NI EZ with Easy Closure



功能

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

完成: 电镀锌

材料: 钢



技术参数



Table 1/2

物料号	订货号	NB/DN	外径 (OD)	杆尺寸 (RS)	宽度 (W)	厚度 (T)
MPZ032	595054	25	32.0 - 33.7 mm	M10	30 mm	1.5 mm
MPZ025	595053	20	25.0 - 26.9 mm	M10	30 mm	1.5 mm
MPZ040	595056	32	40.0 - 42.4 mm	M10	30 mm	1.5 mm
MPZ020	595052	15	20.0 - 21.3 mm	M10	30 mm	1.5 mm

物料号	订货号	NB/DN	外径 (OD)	杆尺寸 (RS)	宽度 (W)	厚度 (T)
MPZ063	595059	50	60.3 - 63 mm	M10	30 mm	2 mm
MPZ090	595062	80	88.9 - 90 mm	M10	30 mm	2 mm
MPZ050	595057	40	48.3 - 50 mm	M10	30 mm	2 mm
MPZ075	595061	65	75.0 - 76.1 mm	M10	30 mm	2 mm
MPZ110	595063	100	110.0 - 114.3 mm	M10	30 mm	2.5 mm
MPZ140	595066	125	139.7 - 141 mm	M10	30 mm	2.5 mm

Table 2/2

物料号	订货号	静态负载	认证
MPZ032	595054	1125N	FM Approved, Pipe Hanger Components, AON Fire Protection, Macrofix Plus NI EZ
MPZ025	595053	1125N	AON Fire Protection, BB019, pipe hangers, FM Approved, Pipe Hanger Components
MPZ040	595056	1125N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ020	595052	1125N	AON Fire Protection, BB019, pipe hangers
MPZ063	595059	1725N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ090	595062	1725N	
MPZ050	595057	1725N	FM Approved, Pipe Hanger Components, AON Fire Protection, Macrofix Plus NI EZ
MPZ075	595061	1725N	
MPZ110	595063	2000N	
MPZ140	595066	2000N	

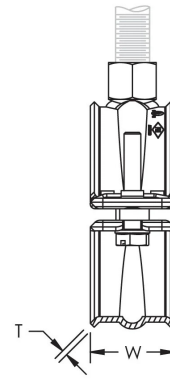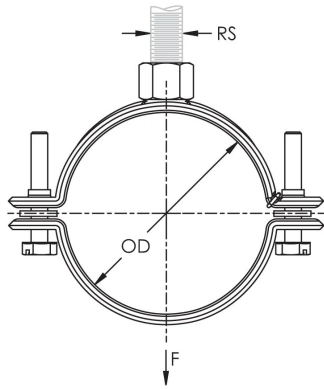

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

