

A12 Standard Coupler for Cryogenic Applications, 32 mm, #10

物料号

EL32A12CRN

The nVent LENTON brand of cryogenic reinforcement splicing systems should be specified whenever cryogenic-grade reinforcing bar is used, or during normal operating or emergency conditions where the temperature falls below -20 °C (-4 °F). By combining the nVent LENTON taper-threaded couplers with state-of-the-art materials, we have developed one of the slimmest couplers on the market, while still maintaining top performance. Typical construction projects include LNG and LPG storage tanks.



功能

Designed to splice the same diameter bars where the second bar can be rotated and is not restricted in its axial direction

Slim design maintains concrete cover

Installs quickly and easily

Improved performance and reliability at cryogenic temperatures (-168 °C / -270 °F)

产品属性

材料: 不锈钢 431 (EN 1.4057)

完成: 普通

钢筋尺寸, 公制: 32 mm

钢筋尺寸, 美国: #10


直径 (Ø): 45 mm

长度 (L): 108mm
杆深 (BD): 45mm
杆间隙 (BG): 18mm
单位重量: 0.79 kg
设计符合: ACI 318 1 型 (125% 指定屈服强度) ;ACI 318 2 型 (指定抗拉强度) ;AS3600;BS EN 1992-1-1;DIN EN 1992-1-1;EN 14620-3;欧洲标准 2
包装数量: 15

其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

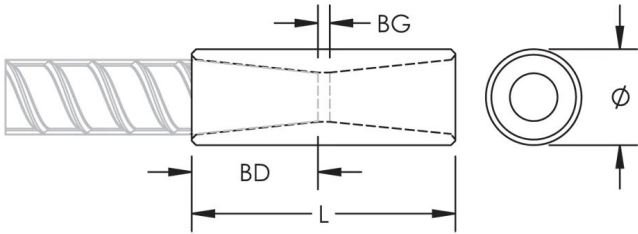

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE