

nVent LENTON Interlok Position Grout-Fill Coupler



功能

Designed to splice the same diameter bars

Smaller bars can be installed into the over-sized cavity end if required

Positional feature allows the threaded coupler end to telescope out to close a gap between forms and to allow alignment of the grout tubes

Over-sized cavity allows for greater field tolerance

Taper-threaded end helps prevent movement of the reinforcing bars and eliminate misalignment

Requires less grout than most competitive systems

材料: 铸铁

完成: 普通

技术参数

Table 1/2						
物料号	包装	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 1 (Ø1)	直径 2 (Ø2)
LK6STHD	标准	20 mm	#6	20M	65 mm	48 mm
LK6STHDPKG	散装	20 mm	#6	20M	65 mm	48 mm
LK11STHD	标准	36 mm	#11	35M	80 mm	62 mm
LKT14STHD	标准	43 mm	#14	45M	94 mm	70 mm

Table 2/2							
物料号	长度 1 (L1)	长度 2 (L2)	长度 3 (L3)	杆深 (BD)	联轴器主体 (CB)	单位重量	包装数量
LK6STHD	265 mm	284 mm	156mm	28mm	200mm	2.42 kg	8
LK6STHDPKG	265 mm	284 mm	156mm	28mm	200mm	2.42 kg	
LK11STHD	389 mm	414 mm	251mm	43mm	305mm	4.59 kg	4
LKT14STHD	485 mm	505 mm	312mm	56mm	386mm	8.3 kg	2


设计符 AASHTO;ABNT NBR 8548:1984;ACI 318 1 型（125% 指定屈服强度）;ACI 318 2 型（指定抗拉强度）;ACI
合: 349;ACI 359;AS3600

其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

Prior to installation, please read and understand the detailed instructions and safety notices provided in the nVent LENTON Interlok Instruction Manual.

图

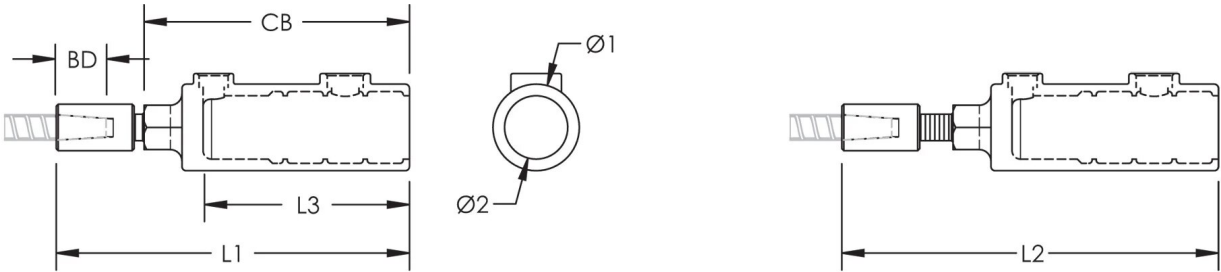

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE