

nVent LENTON Interlok Standard Grout-Fill Coupler, Plain



功能

Designed to splice the same diameter bars

Smaller bars can be installed into the over-sized cavity end if required

Over-sized cavity allows for greater field tolerance

Taper-threaded end helps prevent movement of the reinforcing bars and eliminate misalignment

Requires less grout than most competitive systems

材料: 铸铁

完成: 普通

包装: 标准



技术参数

Table 1/2

物料号	订货号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 1 (Ø1)	直径 2 (Ø2)
LK5		16 mm	#5	15M	65 mm	48 mm
LK16		16 mm	#5	15M	59 mm	41 mm
LK11	145605	36 mm	#11	35M	80 mm	62 mm
LK7	145585	22 mm	#7		65 mm	48 mm
LK6	145580	20 mm	#6	20M	65 mm	48 mm
LK8	145590	25 mm	#8	25M	68 mm	51 mm
LK20		20 mm	#6	20M	62 mm	45 mm
LK9	145595	28 mm	#9	30M	71 mm	54 mm


物料号	订货号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 1 (Ø1)	直径 2 (Ø2)
LK25		25 mm	#8	25M	68 mm	51 mm
LK10	145600	32 mm	#10		76 mm	59 mm
LK12		38 mm			94 mm	70 mm
LK36		36 mm	#11	35M	81 mm	62 mm
LKT14	145611	43 mm	#14	45M	94 mm	70 mm
LK40		40 mm			94 mm	70 mm

Table 2/2							
物料号	订货号	长度 1 (L1)	长度 2 (L2)	杆深 (BD)	单位重量	包装数量	认证
LK5		200 mm	156 mm	22mm	1.98 kg	12	
LK16		201 mm	168 mm	24mm	1.69 kg	110	IAPMO®-UES, LA City Approval
LK11	145605	305 mm	251 mm	43mm	3.63 kg	1	IAPMO®-UES, LA City Approval
LK7	145585	200 mm	156 mm	32mm	1.94 kg	1	LA City Approval, IAPMO®-UES
LK6	145580	200 mm	156 mm	28mm	1.96 kg	12	IAPMO®-UES, LA City Approval
LK8	145590	219 mm	178 mm	34mm	2.15 kg	8	IAPMO®-UES, LA City Approval
LK20		226 mm	178 mm	35mm	1.98 kg	12	IAPMO®-UES, LA City Approval
LK9	145595	248 mm	203 mm	38mm	2.44 kg	8	LA City Approval, IAPMO®-UES
LK25		228 mm	178 mm	40mm	2.26 kg	8	
LK10	145600	275 mm	229 mm	40mm	2.84 kg	8	LA City Approval, IAPMO®-UES
LK12		386 mm	324 mm	44mm	7.14 kg	4	
LK36		313 mm	251 mm	52mm	4.04 kg	8	
LKT14	145611	386 mm	324 mm	56mm	7.26 kg	4	IAPMO®-UES, LA City Approval
LK40		386 mm	324 mm	57mm	6.33 kg	4	

其他产品详情

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

Prior to installation, please read and understand the detailed instructions and safety notices provided in the nVent LENTON Interlok Instruction Manual.

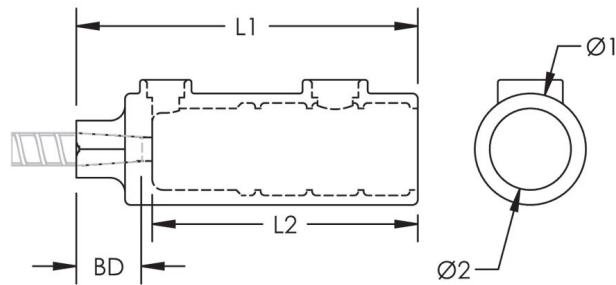

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美

+1.800.753.9221
，按 1 转客户服务
，按 2 转技术支持

欧洲

荷兰：
+31 800-0200135
法国：
+33 800 901 793

欧洲

德国：
800 1890272
其他国家/地区：
+31 13 5835404

亚太地区

上海：
+ 86 21 2412 1618/19
悉尼：
+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE