


凸缘螺钉, 十字槽/开槽

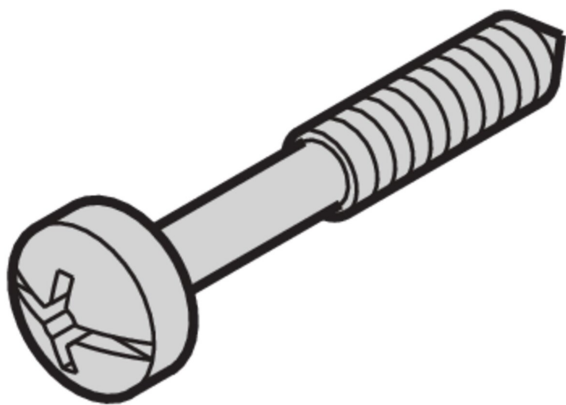

类型: 螺钉
产品类型: 螺钉



技术参数

Table 1/2

物料号	直径	长度	材料	完成	包装数量	螺纹尺寸
21102-026	2.5mm	12.3mm	钢	镀镍	100	M2.5
21101-102		12.3mm	钢	锌面涂层	100	M2.5
21101-906		12.3mm	不锈钢		100	M2.5
21101-101		12.3mm	钢	镀镍	100	M2.5
21101-323		11mm			100	M2.5

Table 2/2

物料号	深度	高度	宽度	搭配	螺纹类型	扭矩	认证
21102-026				框架式插入单元, 模件盒		0.3N · m	
21101-102	14.3mm	5mm	5mm	前面板	公制	0.3N · m	RoHS
21101-906				前面板		0.3N · m	RoHS
21101-101	14.3mm	5mm	5mm	前面板	公制	0.3N · m	RoHS
21101-323				前面板			

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE