


组合式机箱安装套件

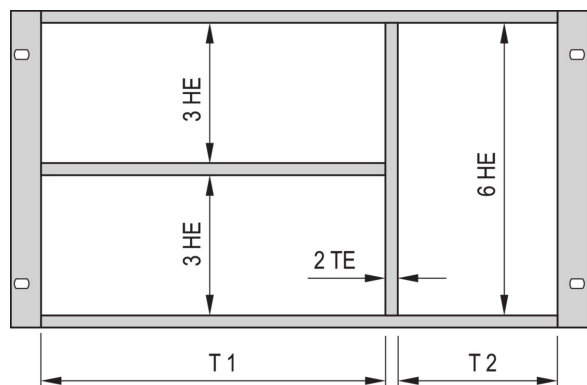

组合安装可将 6 U 高插槽或机箱拆分为 2 x 3 U 和 6 U 两部分。可提供不同版本。

功能

旨在安装欧卡电路板（100 mm 高）和双高度欧卡电路板（233.35 mm 高）

6 U 装配区可拆分成：2 x 3 U, 1 x 6 U

机架高度: 6U
类型: 组合式
产品系列: EuropacPRO
产品类型: 安装套件
搭配: 插槽



技术参数

物料号	包装数量	机架宽度 1	机架宽度 2	材料
24562-440	1	40HP	42HP	铝, 锌合金
24562-442	1	42HP	40HP	铝, 锌合金
24562-484	1	84HP		铝, 锌合金
24562-420	1	20HP	62HP	铝, 锌合金
24562-463	1	63HP	19HP	铝, 锌合金

其他产品详情

Please order separately: 前面板 6 U, 2 HP to cover the strut.

The following guide rails cannot be used: type "accessory", type "accessory, strengthened" and type "for 4.4" PCB".

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent

的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE