

RatiopacPRO EMC 前面板，开槽，屏蔽，3U，42 HP，2.5毫米，铝，前部经阳极氧化，后部导电

物料号

24572-604


EMC

前面板可以插入具有抬高设计的特殊水平轨道中。无需螺钉即可固定。此设计可方便用户使用前面板贴膜。

功能

无螺钉固定

特殊的水平轨道覆盖前面板（顶部和底部）的边缘，防止前面板弯曲

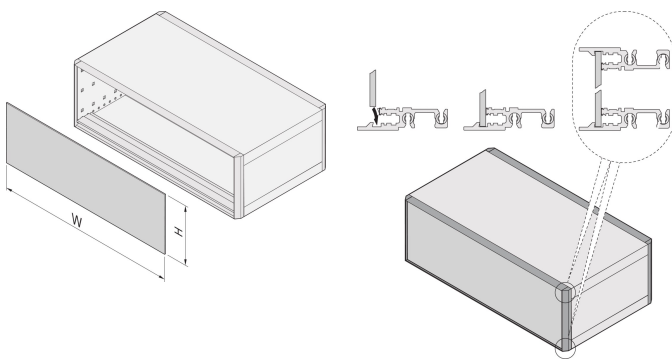

产品属性

机架高度: 3U

机架宽度: 42HP

附件类型: 前面板

包装数量: 1

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

深度: 2.5mm

完成: 阳极氧化; 钝化

高度: 128.4mm

材料: 铝

产品类型: 前面板

宽度: 213.2mm

净重: 0.55kg

*所示价格为每件价格，不含增值税。是否含包装费和运费取决于当地情况。如果这些费用应为总价的一部分，报价中将包含包装费和运费。给定的价格为非约束性建议零售价 (RRP)，即 nVent 标价。当地经销商的最终销售价格可能会有所不同。在 SCHROFF.nVent.com 上请求或生成的报价仅对商业客户 (B2B) 有效。上面显示的交货时间是从 nVent SCHROFF 工厂发货该项目的估计值。运输时间不包括在此估计中，因为运输时间可能会有所不同，具体取决于送货地址、包裹尺寸和其他因素。对于配置的产品，在非推荐区域（“检测到的碰撞区域”）进行的开孔和修改可能会产生额外的工程和/或设计成本，这可能会增加最初的报价。

其他产品详情

要获得屏蔽型机箱，必须安装所有 EMC 密封件（前面板/后面板 - 侧板）水平轨道；侧板 - 盖板；前面板/后面板 - ；水平轨道 - 水平轨道）。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE