


EuropacPRO Advanced EMC Side Panel Cover

Aluminium Side panel 3mm to increase the EMC shielding effect of the subrack by covering the not needed cut-outs.

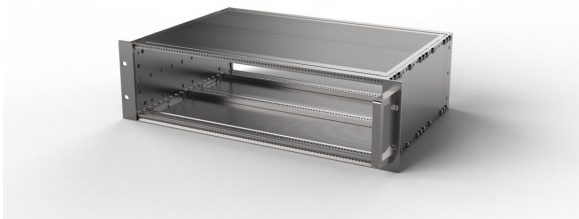

功能

用于增强横向射频屏蔽功能的侧面板盖

装配在标准侧面板外侧

内含装配材料

材料: 铝
产品系列: EuropacPRO
完成: 钝化
产品类型: 侧面板
搭配: 插箱
类型: H 型
EMC 屏蔽: 是



技术参数

Table 1/2

物料号	机架高度	深度	包装数量	长度	包装单位
24563-256	3U	235mm	2	235mm	对
24563-268	4U	355mm	2	355mm	对
24563-257	3U	275mm	2	275mm	对
24563-269	4U	415mm	2	415mm	对
24563-267	4U	295mm	2	295mm	对
24563-266	4U	235mm	2	235mm	对
24563-270	4U	495mm	2	495mm	对
24563-265	4U	175mm	2	175mm	对

物料号	机架高度	深度	包装数量	长度	包装单位
24563-275	6U	175mm	2	175mm	对
24563-258	3U	277.75mm	2	277.75mm	对
24563-276	6U	235mm	2	235mm	对
24563-262	3U	495mm	2	495mm	对
24563-277	6U	275mm	2	275mm	对
24563-261	3U	415mm	2	415mm	对
24563-278	6U	277.75mm	2	277.75mm	对
24563-279	6U	295mm	2	295mm	对
24563-260	3U	355mm	2	355mm	对
24563-280	6U	355mm	2	355mm	对
24563-281	6U	415mm	2	415mm	对
24563-259	3U	295mm	2	295mm	对

Table 2/2					
物料号	机架高度	深度	包装数量	长度	包装单位
24563-282	6U	495mm	2	495mm	对
24563-255	3U	175mm	2	175mm	对

其他产品详情

侧板和 19 寸角规以Tox 方式连接。toxen = 不需要辅助物料的铆接技术。通过特殊工具和高压力方式实现。

可应要求提供 9 U 高度的。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE