


EuropacPRO

盖板，适合用螺钉固定至加固型侧板

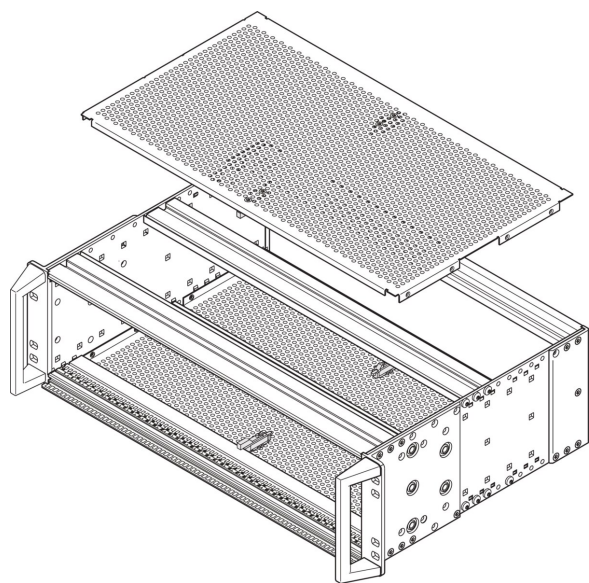

盖板用于提供电磁屏蔽或机械保护。

功能

通风率 58%

机架宽度: 84HP
材料: 铝
产品类型: 盖板
产品系列: EuropacPRO
完成: 钝化
类型: 穿孔
搭配: 插箱



技术参数

物料号	深度	包装数量	包装单位	扭矩
24568-004	175mm	2	对	2.1N · m
24568-036	277.75mm	2	对	2.1N · m
24568-032	275mm	2	对	2.1N · m
24568-020	355mm	2	对	2.1N · m
24568-016	295mm	2	对	2.1N · m
24568-012	295mm	2	对	2.1N · m

物料号	深度	包装数量	包装单位	扭矩
24568-008	235mm	2	对	2.1N • m

其他产品详情

可选的顶盖锁定机构也可以将顶盖固定在前后横梁上。

每个插箱都需要 4 个不锈钢 EMC 屏蔽条进行屏蔽，请单独订购。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE