


EuropacPRO Rear Angle for Textile EMC Gasket

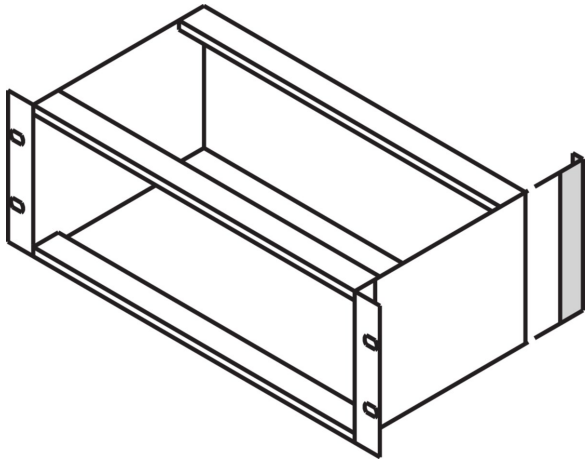

适用于 EMC 垫片的 EuropacPro

后角规，由铝挤压件制成，表面蚀刻。无法同时安装后罩。

功能

适用于后部屏蔽需要

若有安装深度调节 19 寸支架，也可用于机箱前部

材料: 铝
产品类型: 盖板
产品系列: EuropacPRO
类型: 后法兰
搭配: 插箱



技术参数

物料号	机架高度	包装数量	高度	包装单位
24564-199	3U	2	132.6mm	对
24564-799	9U	2	399.3mm	对
24564-299	4U	2	177mm	对
24564-499	6U	2	265.9mm	对

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent

的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE