

前面板, Front Shielded, 侧面铰链固定

带导电布EMC垫片的面板，侧面铰链固定。

功能

前面板，带纺织物 EMC 垫片

可安装到水平轨道上

适用于插箱和仪器箱

可在左或右安装铰链

深度 (D): 2.5mm
机架宽度: 84HP
材料: 铝
完成: 阳极氧化; 钝化
附件类型: 前面板
产品类型: 前面板
类型: 不带把手的前面板
EMC 屏蔽: 无 (可改装)





技术参数

Table 1/2

物料号	机架高度	包装数量	安装	垫片类型	正面表面处理	反面表面处理
20848-611	3U	1	铰链式，侧面	织物 EMC	阳极氧化	导电
20848-617	6U	1	铰链式，侧面	织物 EMC	阳极氧化	导电

Table 2/2

物料号	边缘处理	高度 (H)	宽度 (W)
20848-611	否	128.4mm	426.4mm
20848-617	否	261.8mm	426.4mm

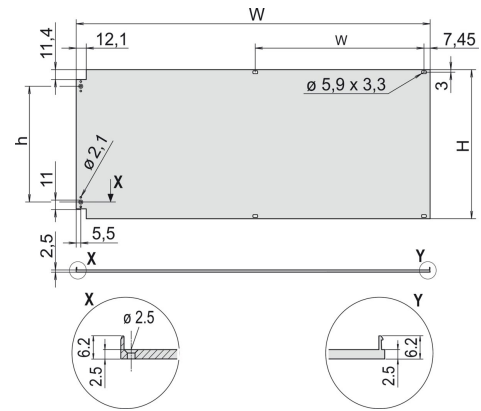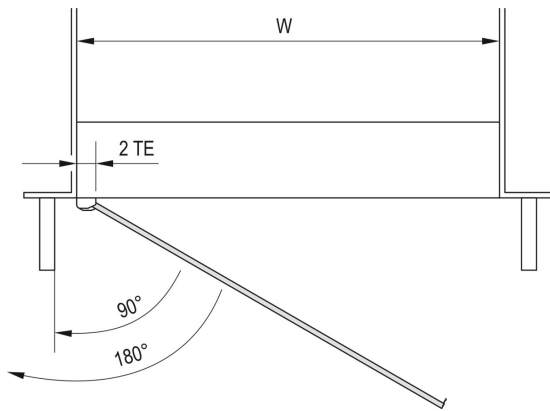

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE