


水平轨道螺母条, M2.5

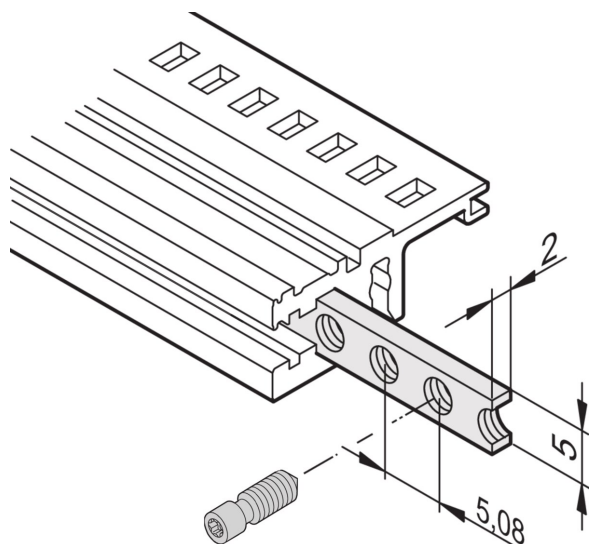

螺母条是一种带 M2.5 螺纹的金属条，可用于固定前面板。

功能

用于固定部分宽度前面板的凸缘螺钉，必须是 12.3 mm 长

适用于所有水平横梁

搭配: 插箱; 仪器箱
产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac
材料: 钢
产品类型: 螺纹嵌件
完成: 镀锌



技术参数

物料号	机架宽度	包装数量	长度
34561-328	28HP	1	146.82mm
34561-363	84HP	1	324.62mm
34561-384	84HP	1	431.3mm
34561-342	42HP	1	217.94mm
34565-196	196HP	1	1000.26mm
34561-320	20HP	1	106.18mm
34561-340	40HP	1	207.78mm

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE