


# LHX+ Fan Tray

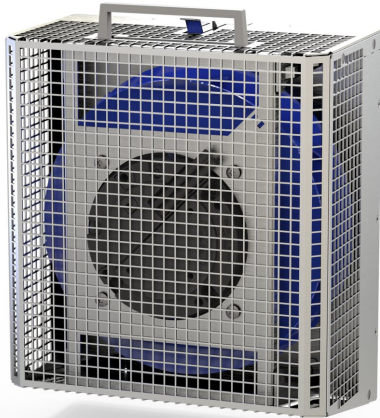

## 功能

LHX+ Fan trays allow for easy and hot swappable replacement of fans

产品类型: 风扇盘

## 技术参数

Table 1/2

| 物料号       | 高度       | 宽度       | 深度      | 搭配                    | 包装数量 | 气流方向 |
|-----------|----------|----------|---------|-----------------------|------|------|
| 29714-025 | 244.24mm | 215.15mm | 126.3mm | Varistar, Varistar CP | 1    | 前对顶  |
| 29714-026 | 244.24mm | 443.4mm  | 126.3mm | Varistar, Varistar CP | 1    | 前对顶  |

Table 2/2

| 物料号       | 颜色  | 颜色代码     | 风扇数量 | 完成  | 交流输入电压 | 材料 |
|-----------|-----|----------|------|-----|--------|----|
| 29714-025 | 浅灰色 | RAL 7035 | 1    | 镀锌铝 | 230V   | 钢  |
| 29714-026 | 浅灰色 | RAL 7035 | 1    | 镀锌铝 | 230V   | 钢  |

## 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

## North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE