


盘头螺钉, Torx, 自固定

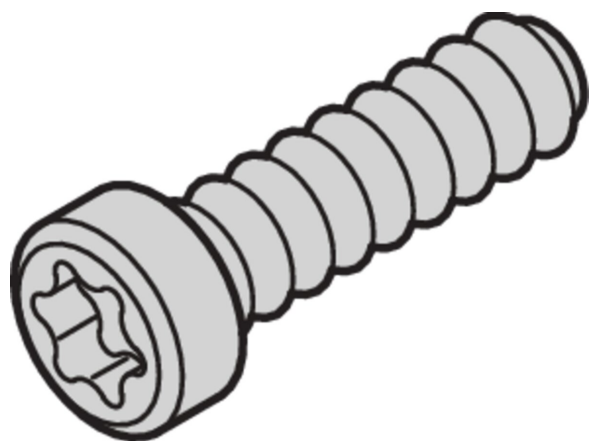

不同公制螺纹和长度的盘头星形螺钉。可选功能包括接地功能或“预涂层螺纹”。

盘头螺钉, 内梅花, 镀锌钢制, M2.5 x 6 (部分螺纹涂有螺纹胶, 防止螺钉因振动而松脱)

功能

内梅花盘头螺钉, 自锁式

类型: 盘头螺钉
产品类型: 螺钉
材料: 钢



技术参数

物料号	长度	完成	包装数量	螺纹尺寸	搭配
24560-159	6mm	镀锌	100	M2.5	背板, 测试适配器
21500-039	9.3mm	镀锌	100	M2.5	前面板, H 型横梁, R 型横梁

其他产品详情

最大扭矩 0.2 Nm。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书, 或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告, 可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE