


适用连接器的 Z 形轨道, EN 60603-2, DIN 41612

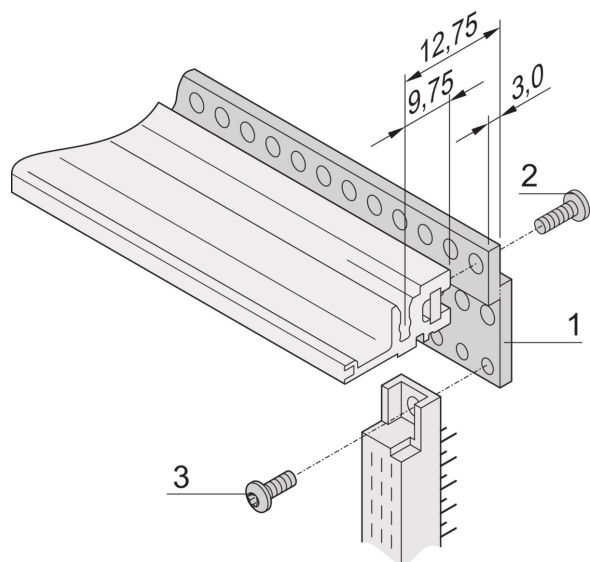

适用连接器的 Z 形轨道, 符合 EN 60603-2 (DIN 41612) 标准。

功能

铝挤压件, 阳极氧化

Z 型轨用螺栓固定在插箱上, 以安装连接器 (后水平轨道 ST 型), 插入螺纹插件, 绝缘条)

适用于符合 EN 60603 - 2 (DIN 41612) 的连接器

材料: 铝
完成: 阳极氧化
搭配: 插箱; 仪器箱
产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO
产品类型: Z 形导轨



技术参数

物料号	机架宽度	包装数量	长度
30822-025	20HP	1	101.6mm
30822-045	40HP	1	203.2mm

其他产品详情

将 Z 形轨道安装在水平轨道上需要螺纹插件和内梅花盘头螺钉; 请单独订购。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书, 或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告, 可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE