

Adjustable I-Beam Adapter



This code-compliant Structural Attachment is part of the nVent CADDY line of innovative rigid bracing system, designed to provide superior performance and meet the highest seismic load requirements. Its innovative design allows quick and easy installation onto a wide range of steel I-Beams. It is ready to use out of the box, eliminating the need for pre-assembly or loose hardware and its snap-off bolts make inspection of seismic sway braces simple.

功能

No loose parts

No assembly required

Snap-off bolt head helps enable easy installation and inspection of seismic sway braces

Meets NFPA®-13 requirements for seismic sway bracing

FM® Specification Tested

材料: 钢



技术参数

Table 1/2

物料号	完成	法兰厚度 (FT)	A	杆尺寸 1 (RS1)	杆尺寸 2 (RS2)	高度 (H)
CSBS3HDN	热浸镀锌	6 - 19 mm	100 - 215 mm	3/8"	1/2"	67 mm
CSBS4N	电镀锌	6 - 19 mm	100 - 365 mm	3/8"	1/2"	67 mm
CSBS4HDN	热浸镀锌	6 - 19 mm	100 - 365 mm	3/8"	1/2"	67 mm
CSBS3N	电镀锌	6 - 19 mm	100 - 215 mm	3/8"	1/2"	67 mm
CSBS5HDN	热浸镀锌	19 - 31 mm	100 - 455 mm	3/8"	1/2"	79 mm
CSBS5N	电镀锌	19 - 31 mm	100 - 455 mm	3/8"	1/2"	79 mm

Table 2/2

物料号	宽度 (W)	认证
CSBS3HDN	92 mm	FM Approved, Seismic
CSBS4N	92 mm	FM Approved, Seismic, AON Fire Protection, Seismic Bracing Components
CSBS4HDN	92 mm	FM Approved, Seismic
CSBS3N	92 mm	AON Fire Protection, Seismic Bracing Components, FM Approved, Seismic
CSBS5HDN	92 mm	FM Approved, Seismic
CSBS5N	92 mm	AON Fire Protection, Seismic Bracing Components, FM Approved, Seismic


其他产品详情

Structure Attachment and Brace Member are not included.

UL Loads				
Part Number	Structure Attachment Fitting	Flange Thickness	Brace Member	Load Rating
CSBS3xxx	CSBU1xxx	6 - 8 mm	DN25 - DN50 Sch. 40 NPS	6672 N
		8 - 19 mm		7561 N
	CSBURC12	6 - 19 mm	CSB12CBL	1859 N
			CSB18CBL	3434 N
			CSB36CBL	4893 N
CSBS4xxx	CSBU1xxx	6 - 8 mm	DN25 - DN50 Sch. 40 NPS	6672 N
		8 - 19 mm		7561 N
	CSBURC12	6 - 19 mm	CSB12CBL	1859 N
			CSB18CBL	3434 N
			CSB36CBL	4893 N
CSBS5xxx	CSBU1xxx	6 - 19 mm	DN25 - DN50 Sch. 40 NPS	7561 N
	CSBURC12	6 - 19 mm	CSB12CBL	1859 N
			CSB18CBL	3434 N
			CSB36CBL	4893 N

FM Loads								
Part Number	Horizontal Capacity per Installation Angle from Vertical							
	Perpendicular to Structure				Parallel to Structure			
	30°- 44°	45°- 59°	60°- 74°	75°- 90°	30°- 44°	45°- 59°	60°- 74°	75°- 90°
CSBS3xxx	5240 N	9830 N	12580 N	13070 N	3640 N	6130 N	9250 N	13380 N
CSBS4xxx	5240 N	9830 N	12580 N	13070 N	3640 N	6130 N	9250 N	13380 N
CSBS5xxx	5420 N	9510 N	11470 N	12760 N	4890 N	8090 N	9740 N	11920 N

图

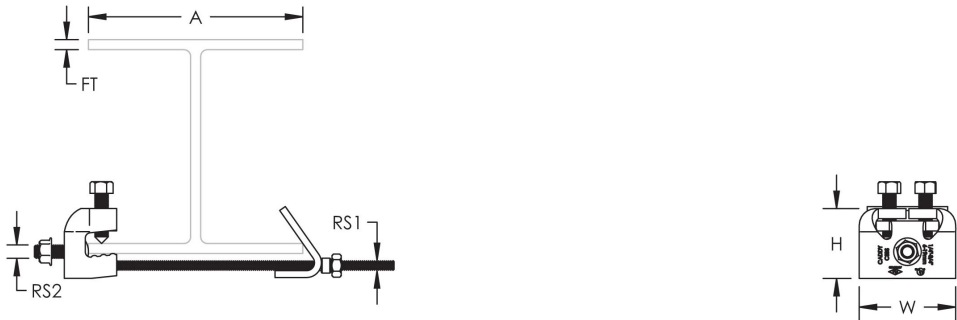

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美 +1.800.753.9221 ，按 1 转客户服务 ，按 2 转技术支持	欧洲 荷兰： +31 800-0200135 法国： +33 800 901 793	欧洲 德国： 800 1890272 其他国家/地区： +31 13 5835404	亚太地区 上海： + 86 21 2412 1618/19 悉尼： +61 2 9751 8500
--	---	---	--



我们强大的品牌组合：
 CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

