


nVent CADDY Pyramid Equipment Support Kit, 4 Post Base

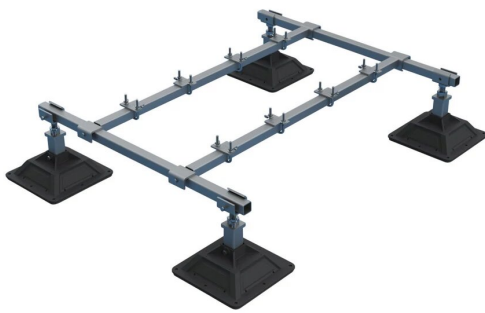

功能

Kit includes post-base assemblies, frame and equipment-support clamps

Assembles and adjusts to size and height in minutes by one person with one tool

Innovative crossbar and equipment-support clamps enable quick assembly

Integral foam pad provides gentle interface for all roof types

Hot-dip galvanized and UV stabilized for long lasting performance

Assembled support can be lifted as one unit and easily relocated



技术参数

Table 1/3

物料号	订货号	材料	完成	温度	高度 (H)	长度 (L)
PEK4B	360426	钢, 聚丙烯, 聚乙烯	热浸镀锌	-34 to 54.4 °C	305 - 457 mm	1257mm

Table 2/3

物料号	订货号	后基座 (A)	方形管 (B)	横杆总成 (C)	宽度 (W)	表面积
PEK4B	360426	314 mm x 4 pc	1067 mm x 2 pc	1232 mm x 2 pc	1588 mm	0.36m ²

Table 3/3				
物料号	订货号	单位重量	极限静态负载 (F)	静态负载安全系数
PEK4B	360426	36 kg	4980N	3:1

其他产品详情

Static load must be stable and uniformly distributed across frame.

图



警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

