


Cable Anchorage Glands For Wall Mounted Enclosures, CAG

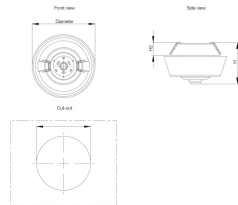

This two component cable gland can be mounted on a wide range of enclosures. It secures the cable into position, and eliminates any external strains.

功能

Description: Two-component grommet with membrane seal and cable anchorage. The installation does not require tools, it is self-adjusting to its surrounding wall thickness and click-fixed in place. Because of its compact design it only extends 5.7 mm outside the enclosure on which it is mounted. The “pushout” membrane is a permanent seal until it is penetrated by a cable or pipe. Suitable for holes in materials of 0.7 to 3 mm thickness.

Material: TPE and polyamide 66, halogen free.

Temperature resistance: -20 °C to +125 °C.

Finish: RAL 7035.


Protection: IP 67, 65, waterproof.

Pack quantity: 50 pieces.

颜色: 浅灰色
材料: 塑料
颜色代码: RAL 7035
完成: 平滑

技术参数

物料号	高度 (H)	宽度 (W)	深度 (D)	高度 (H)	直径 (Ø)	电缆直径范围
CAG20	19.5mm	30.7mm	30.7mm	17 – 20mm	34 – 37mm	7 – 11mm
CAG25	19.7mm	35.7mm	35.7mm	17 – 20mm	39 – 42mm	7 – 13mm

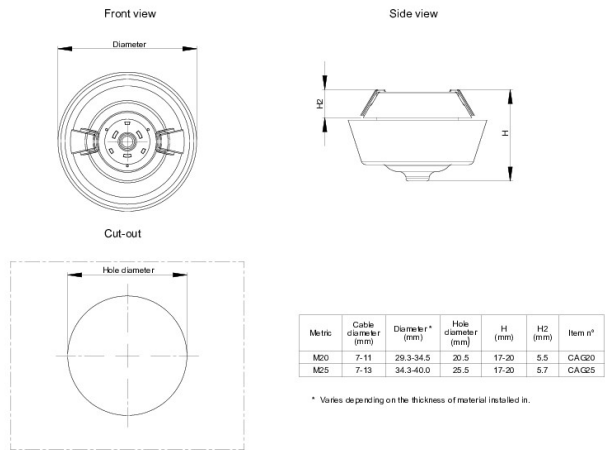

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE