

不锈钢，双门机柜，ADR



The double door wall mounted stainless steel enclosure range, ADR, is ideal for installation in confined spaces where a single door, when opened, would take up too much space in front of the enclosure. The doors' loading capacity also increases as it is divided over two doors. With a IP 55 protection degree, components inside the enclosure are well protected and makes it well suited for industries such as food and beverage and pharmaceuticals, as well as almost all other environments, grade dependant.

工业标准

cUL 认证（根据 CSA C22.2 No.0、No.0.4、No.14、No.94; Type 12; 文件编号 E92044

cUL Listed per CSA C22.2 No.0, No.0.4, No.14, No.94; Type 12; File No. E61997

CSA, 文件编号 1442951) : Type 12

CSA, File No. 1442951: Type 12

IEC 62208 IP55

CE, UK CA, UL, DNV

功能

Material: AISI 304L / AISI 316L pre-grained stainless steel. Body: 1.5 mm. Door: 2 mm. Mounting plate: 2.5 mm galvanized steel.

Body: Folded and seam welded. For ease of installation, each back corner of the enclosure is laser-marked to precisely indicate where to drill holes and affix AWS wall mounting brackets.

Door: Corner formed in one piece. Surface mounted, with 130° opening. Concealed AISI 304 stainless steel hinges with captive pin. Sealing is ensured by an injected polyurethane gasket or by an injected silicone gasket. Inner M6 welded studs to mount optional door profiles MMDP.

Lock: nVent HOFFMAN customized zamak double-bit 3 mm lock, with 90° movement and anti-vibration mechanism. Espagnolette three point locking. Stainless steel lock and other versions are available as accessories.

Mounting plate: The mounting plate is marked vertically at 10 mm intervals, for easy horizontal positioning of equipment. On the top and bottom there are holes to facilitate cable fixing. Fixed onto M8 press welded studs to

the rear of the enclosure. All sides, from 800 mm and above, are strengthened by folded edges. By using the AMG accessory, the mounting plate position can be adjusted to any depth.

Cable access: No gland plate openings as standard, to maximise sealing and cleanliness.

Finish: 400 pre-grained stainless steel.

Protection: Corresponds with IP 55, TYPE 12, IK 10.

Delivery: Enclosure with door, mounting plate, metallic key and mounting accessories.

Additional information: For outdoor environments exposed to precipitation, the use of a rain hood is advised. Also in environments known for quick temperature changes, consideration to condensation should be taken. Please see the thermal management section.


主体厚度: 1.5mm
门厚: 2mm
完成: 拉丝

技术参数

物料号	订货号	高度 (H)	宽度 (W)	深度 (D)	垫片类型	材料
ADR1001230	ADR1001230	1000mm	1200mm	300mm	聚氨酯	不锈钢 304
ADR1201240-316	ADR1201240-316	1200mm	1200mm	400mm	硅树脂	不锈钢 316
ADR1001030-316	ADR1001030-316	1000mm	1000mm	300mm	硅树脂	不锈钢 316
ADR1001230-316	ADR1001230-316	1000mm	1200mm	300mm	硅树脂	不锈钢 316
ADR1001030	ADR1001030	1000mm	1000mm	300mm	聚氨酯	不锈钢 304
ADR1201240	ADR1201240	1200mm	1200mm	400mm	聚氨酯	不锈钢 304

其他产品详情

* 3 point espagnolette locking.

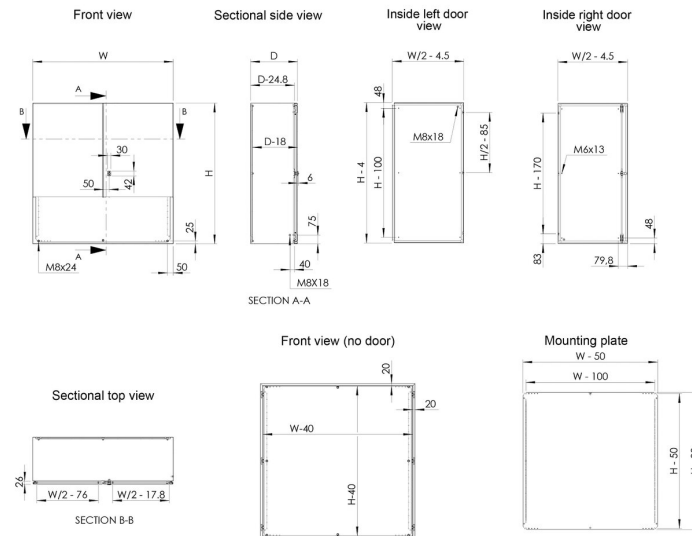

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE