


EL LED 机柜灯

An LED light specially designed for nVent HOFFMAN enclosures. Tool-free assembly reduces the assembly time. Simple through wiring based on a plug and play system.

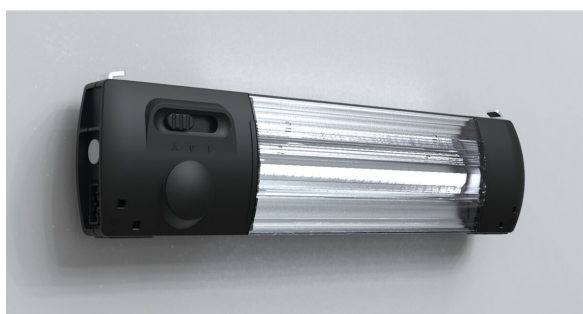

功能

Description: LED enclosure light specially designed for nVent HOFFMAN enclosures. Fast and tool-free assembly thanks to a latching hook system designed to fit the 25mm hole pattern on nVent HOFFMAN enclosures. May be fitted horizontally or vertically.

Please be advised that when using the clamp mechanism to mount these lights, they cannot be installed on the top rail of ProLine and ProLine G2 cabinet frames.

色温: 4000K
工作温度: -20 to 55°C
颜色: 黑色
灯类型: LED
灯光颜色: 中性白色
材料: 塑料
完成: 平滑

技术参数

物料号	订货号	高度	宽度	深度	插座类型	灯输出
EL900D	EL900D	76mm	314mm	48mm	NA	900lm
EL1200D24V	EL1200D24V	76mm	315mm	48mm	NA	1200lm
EL1200M	EL1200M	76mm	315mm	48mm	NA	1200lm
EL900DS-US	EL900DS-US	76mm	364mm	48mm	B 型	900lm
EL1200M24V	EL1200M24V	76mm	315mm	48mm	NA	1200lm
EL1200MS-US	EL1200MS-US	76mm	364mm	48mm	B 型	1200lm

物料号	订货号	高度	宽度	深度	插座类型	灯输出
EL1200DS-US	EL1200DS-US	76mm	364mm	48mm	B 型	1200lm

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE