


极端环境空调

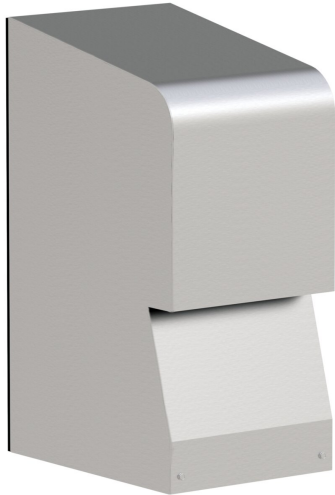

This Extreme Environments Air Conditioner is compact which is ideal for smaller depth enclosures. It supports an energy-efficient rotary compressor with a reliable smart controller. The top is sloped along with sloped internal surface reducing catchpoints for water, dust and bacteria build-up. Cutout Adapter options available for enclosures with older nVent HOFFMAN or Competitive units for easy transitions to this air conditioner.

工业标准

UL/cUL Listed; Type 12, 4, 4X; File No. SA6453

IP34 外部回路

EAC

IP66/IP69/IP69K Internal Loop

IP34 External Loop

Telcordia GR-487 capable

功能

开孔转接器选项，适用于有较旧 nVent HOFFMAN 或具较有竞争力装置的机柜，可轻松转换到新的空调

包括可清洁、可重复使用的铝制网式过滤器，可保护盘管，在污脏环境中实现最佳冷却性能

UL 认证，可节省客户的时间和金钱，且经机构认可

附赠安装五金件、密封条和用户手册，使用更方便。

Energy-efficient rotary compressor

R513A or R134a refrigerant

Reliable Smart Controller on enclosure side of the unit

10-degree sloped top shroud, welded and ground

Sloped internal surfaces reduce catchpoints for water, dust, bacteria build-up

FDA-approved neoprene gasket

No louvers on vertical surfaces allow washdown with minimal protections

Standard Air Conditioner models includes Active condensate management with heater strip, Power-off capability for door switch and other system requirements, Malfunction switch, Corrosion-resistant coating on condenser coil, Compressor heater, Head pressure control, Temperature range from -40 F/-40 C to 131 F/55 C

Manifold set ships with 2 manifolds (1x supply and 1x return) and 2 sets of mounting brackets (total of 4 brackets incl. mounting hardware)

完成: 拉丝 #4
材料: 不锈钢 304

技术参数

物料号	订货号	标称容量 W	标称容量 Btu/h	标称电压	相数	制冷剂
X230226G370	57365	550W	1890Btu/h	230V	1	R134a
X230216G170	57101	675W	2300Btu/h	115V	1	R134a
X230216G370	57364	675W	2300Btu/h	115V	1	R134a
X230226G360	57362	550W	1890Btu/h	230V	1	R134a
X230226G170	57102	550W	1890Btu/h	230V	1	R134a
X230226G160	57104	550W	1890Btu/h	230V	1	R134a
X230216G160	57103	675W	2300Btu/h	115V	1	R134a
X230216G360	57359	675W	2300Btu/h	115V	1	R134a

图



警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE