


Front/Rear Bottom Frames For Floor Standing Enclosures, PCU

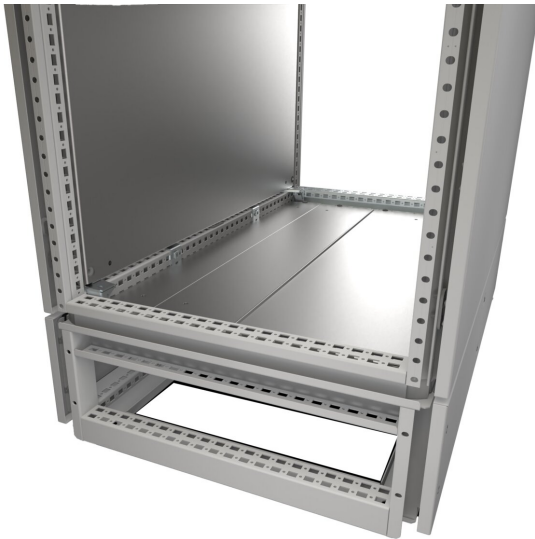

This frame creates additional space in the bottom and can be segregated from the enclosure. It has a universal hole pattern for mounting accessories easily.

功能

Description: For fixing and routing of cables or mounting of busbar. Identical hole pattern to the enclosure's frame makes all relevant accessories (e.g. CLPF, CLPK, etc) possible to mount. Fixed to the base of the enclosure by M12 screws (provided).

Side panels: PCUP supplied as an accessory.

Material: Frame in 1.75 mm steel plate, panels in 1.35 mm steel plate.

Finish: RAL 7035 structured powder coating.

Protection: Complies with IP 55.

Pack quantity: 1 piece with front and back panels including mounting accessories. Add CBP for closing bottom opening.

颜色: 浅灰色
完成: 电镀
颜色代码: RAL 7035
材料: 钢

技术参数

物料号	高度	宽度	深度	外壳材料
PCU2066R5	200mm	599mm	600mm	不锈钢
PCU2108R5	200mm	999mm	800mm	不锈钢
PCU2106R5	200mm	999mm	600mm	不锈钢
PCU2088R5	200mm	800mm	800mm	不锈钢
PCU2086R5	200mm	800mm	600mm	不锈钢
PCU2126R5	200mm	1199mm	600mm	不锈钢
PCU2068R5	200mm	599mm	800mm	不锈钢
PCU2048R5	200mm	400mm	800mm	不锈钢
PCU2128R5	200mm	1199mm	800mm	不锈钢
PCU2046R5	200mm	400mm	600mm	不锈钢
PCU3046R5	300mm	400mm	600mm	不锈钢
PCU3086R5	300mm	800mm	600mm	不锈钢
PCU3088R5	300mm	800mm	800mm	不锈钢
PCU3128R5	300mm	1199mm	800mm	不锈钢
PCU3068R5	300mm	599mm	800mm	不锈钢
PCU3106R5	300mm	999mm	600mm	不锈钢
PCU3126R5	300mm	1199mm	600mm	不锈钢
PCU3066R5	300mm	599mm	600mm	不锈钢
PCU3108R5	300mm	999mm	800mm	不锈钢
PCU3048R5	300mm	400mm	800mm	不锈钢

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合：
CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE