


Hygienic Design Wall Mounted Enclosure, HDW

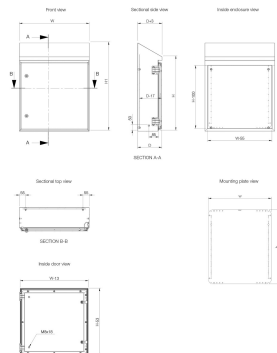

The nVent HOFFMAN Hygienic Design HDW range is designed and constructed with special materials for high sanitary operations and ease of thorough cleaning. The gapless design, the self-drainable high-polished surfaces, together with a high protection degree help reduce non operative hours, such as cleaning and maintenance, which leads to increased productivity.

工业标准

cULus_UL

CE, UK CA, UL

IP

功能

Material: Body: 1.5 mm. Door: 2 mm. AISI 304L pre-grained stainless steel. Mounting plate: 2 mm galvanized steel.

Body: Monoblock body, folded and seam welded. The top of the body is equipped with a sloping roof at an angle of 30° toward the front, ending with a 30 mm overhang to avoid any draining liquids from dripping onto the gasket and the door.

Door: Folded with a sloping angle of 8° on all sides. Surface mounted with 120° opening. Concealed zinc plated steel hinges with captive pin. Can be mounted to give left- or right-hand opening (machining is not required).

Internal hinge: The door hinge is specially designed to be concealed inside the enclosure once the door is closed to avoid dirt from accumulating, making the enclosure easy to clean.

Gasket: A one piece removable blue silicone gasket with molded corners ensures proper sealing, and makes removing and replacing it faster and easier for cleaning and replacement operations. The silicone is FDA 21 CFR 177.2600 compliant.

Lock: HD lock made of stainless steel AISI 316L with blue silicone gasket, the lock conforms with norm DIN EN 1672-2:2009.

Mounting plate: Fixed onto M8 studs welded on the rear of the enclosure. All sides from 800 mm and above are strengthened by folded edges. The mounting plate is marked vertically at 10 mm intervals for easy horizontal

positioning of equipment.

Cable access: No gland openings as standard to avoid hygiene risks.

Protection: Corresponds with IP 66/69, TYPE 4X, 12, 13, IK08.

Finish: 400 Pre-grained stainless steel, polished to Ra < 0.8 µm.


Delivery: Enclosure with door, mounting plate, metallic key and mounting accessories.

Additional information: For accessories on the outside of the enclosure, please see our HD accessories section.

厚度 (T): 1.5mm
斜率: 30°
完成: 拉丝
材料: 不锈钢 304

技术参数

物料号	高度 (H)	宽度 (W)	深度 (D)	面板尺寸
HDW0675121	672mm	510mm	210mm	550 x 450mm
HDW0553921	552mm	390mm	210mm	430 x 330mm
HDW0828130	825mm	810mm	300mm	650 x 750mm
HDW1428130	1425mm	810mm	300mm	1250 x 750mm
HDW0776121	772mm	610mm	210mm	650 x 550mm
HDW0606130	605mm	610mm	300mm	430 x 550mm
HDW0558121	552mm	810mm	210mm	430 x 750mm
HDW0442215	442mm	220mm	155mm	350 x 160mm
HDW0773921	772mm	390mm	210mm	650 x 330mm
HDW1228130	1225mm	810mm	300mm	1050 x 750mm

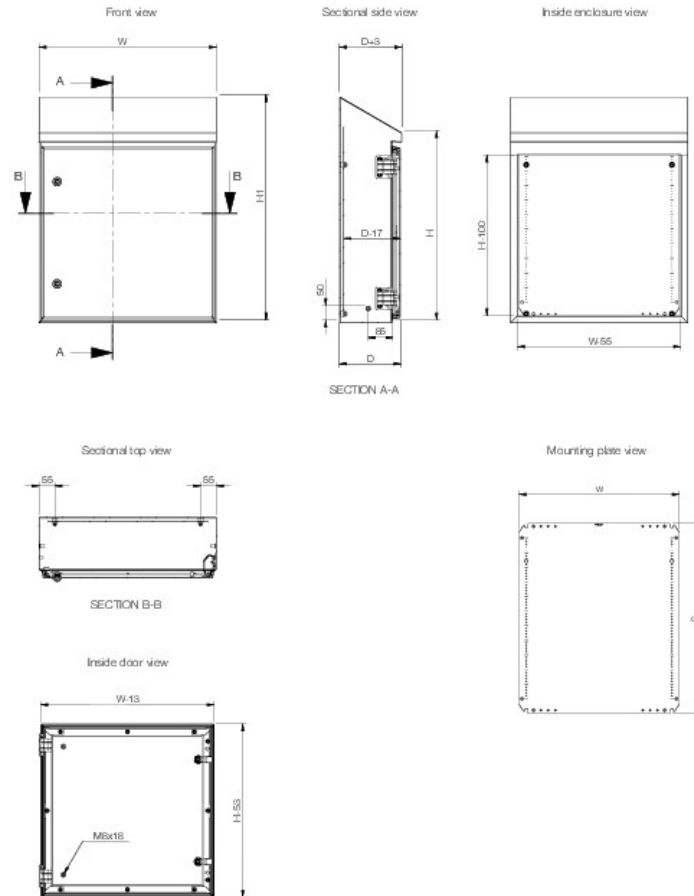

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE