

Mild Steel Single Door Compact Enclosure, MKS



The mild steel single door compact floor standing enclosure range, MKS, with a IP 55 protection degree, is available off the shelf in many different sizes. This enclosure range is well suited for many different applications. The risk for component failure, and with that unnecessary downtime, is eliminated as water and dust are prevented from entering the enclosure.

工业标准

cULus_UL Listed

CE, UK CA, UL

功能

Material: Body: 1.35 mm painted steel. Rear and roof panels: 1.5 mm painted steel. Door: 2 mm painted steel. Mounting plate: 3 mm galvanized steel. Bottom plates: 1 mm galvanized steel.

Body: Four times folded and seam-welded frame. Integrated depth profiles with hole pattern, allowing mounting plate adjustment in depth.

Door: Mounted with four hinges, allowing left or right hand opening. Including door frame with 25 mm hole pattern.

Rear panel: Fitted by M6 torx screws. Standard facilities for rear door mounting.

Roof panel: Removable.

Lock: Espagnolette 4-point locking system. Does not interfere with the enclosure inner space. Standard double-bit lock with 3 mm insert. Standard inserts, cylinders, lift handles and T-handles are available as accessories.

Bottom plates: Consists of three pieces.

Mounting plate: Double folded and slides into position. Adjustable in depth by steps of 25 mm, with the MPD02 accessory. Supplied, attached on the outside of the enclosure packaging.

Earthing: All panels are earthed through their fittings and are equipped with a separate earthing stud.

Finish: RAL 7035 structured powder coating.

Protection: Complies with IP 55 | TYPE 12 | IK 10.

Delivery: Body with fitted door, rear panel, roof panel, bottom plates, mounting plate and door frame (except PE version). Delivery also includes earthing bolts. The enclosure is delivered on a pallet identical to the enclosure width. All packing material is recyclable.

主体厚度: 1.35mm
 门厚: 2mm
 颜色: 浅灰色
 材料: 低碳钢
 完成: 粉末涂层
 颜色代码: RAL 7035

技术参数

Table 1/3

物料号	高度 (H)	宽度 (W)	深度 (D)	包含安装板	面板尺寸	最大安装深度
MKS16104R5	1600mm	1000mm	400mm	是	1494 x 894mm	359mm
MKS16063PER5	1600mm	600mm	300mm	否		
MKS20084PER5	2000mm	800mm	400mm	否		
MKS16105R5	1600mm	1000mm	500mm	是	1494 x 894mm	459mm
MKS16063R5	1600mm	600mm	300mm	是	1494 x 494mm	259mm
MKS14063PER5	1400mm	600mm	300mm	否		
MKS16105PER5	1600mm	1000mm	500mm	否		
MKS20085PER5	2000mm	800mm	500mm	否		
MKS12084R5	1200mm	800mm	400mm	是	1094 x 694mm	359mm
MKS18064PER5	1800mm	600mm	400mm	否		
MKS16064PER5	1600mm	600mm	400mm	否		
MKS20085R5	2000mm	800mm	500mm	是	1894 x 694mm	459mm
MKS16104PER5	1600mm	1000mm	400mm	否		
MKS16064R5	1600mm	600mm	400mm	是	1494 x 494mm	359mm
MKS12084PER5	1200mm	800mm	400mm	否		
MKS20104PER5	2000mm	1000mm	400mm	否		
MKS16085R5	1600mm	800mm	500mm	是	1494 x 694mm	459mm
MKS16083PER5	1600mm	800mm	300mm	否		
MKS18104R5	1800mm	1000mm	400mm	是	1694 x 894mm	359mm
MKS18085R5	1800mm	800mm	500mm	是	1694 x 694mm	459mm

Table 2/3


物料号	高度 (H)	宽度 (W)	深度 (D)	包含安装板	面板尺寸	最大安装深度
MKS14083PER5	1400mm	800mm	300mm	否		
MKS18085PER5	1800mm	800mm	500mm	否		
MKS14083R5	1400mm	800mm	300mm	是	1294 x 694mm	259mm
MKS18104PER5	1800mm	1000mm	400mm	否		
MKS14064R5	1400mm	600mm	400mm	是	1294 x 494mm	359mm
MKS18084R5	1800mm	800mm	400mm	是	1694 x 694mm	359mm
MKS14084PER5	1400mm	800mm	400mm	否		
MKS20084R5	2000mm	800mm	400mm	是	1894 x 694mm	359mm
MKS18084PER5	1800mm	800mm	400mm	否		
MKS20064PER5	2000mm	600mm	400mm	否		
MKS14064PER5	1400mm	600mm	400mm	否		
MKS18064R5	1800mm	600mm	400mm	是	1694 x 494mm	359mm
MKS14084R5	1400mm	800mm	400mm	是	1294 x 694mm	359mm
MKS20064R5	2000mm	600mm	400mm	是	1894 x 494mm	359mm
MKS14063R5	1400mm	600mm	300mm	是	1294 x 494mm	259mm
MKS16084PER5	1600mm	800mm	400mm	否		
MKS20104R5	2000mm	1000mm	400mm	是	1894 x 894mm	359mm
MKS16083R5	1600mm	800mm	300mm	是	1494 x 694mm	259mm
MKS12064PER5	1200mm	600mm	400mm	否		
MKS12064R5	1200mm	600mm	400mm	是	1094 x 494mm	359mm

Table 3/3

物料号	高度 (H)	宽度 (W)	深度 (D)	包含安装板	面板尺寸	最大安装深度
MKS16084R5	1600mm	800mm	400mm	是	1494 x 694mm	359mm
MKS20105R5	2000mm	1000mm	500mm	是	1894 x 894mm	459mm
MKS20105PER5	2000mm	1000mm	500mm	否		
MKS16085PER5	1600mm	800mm	500mm	否		

其他产品详情

For added cabling options, add plinths PF and PCP.

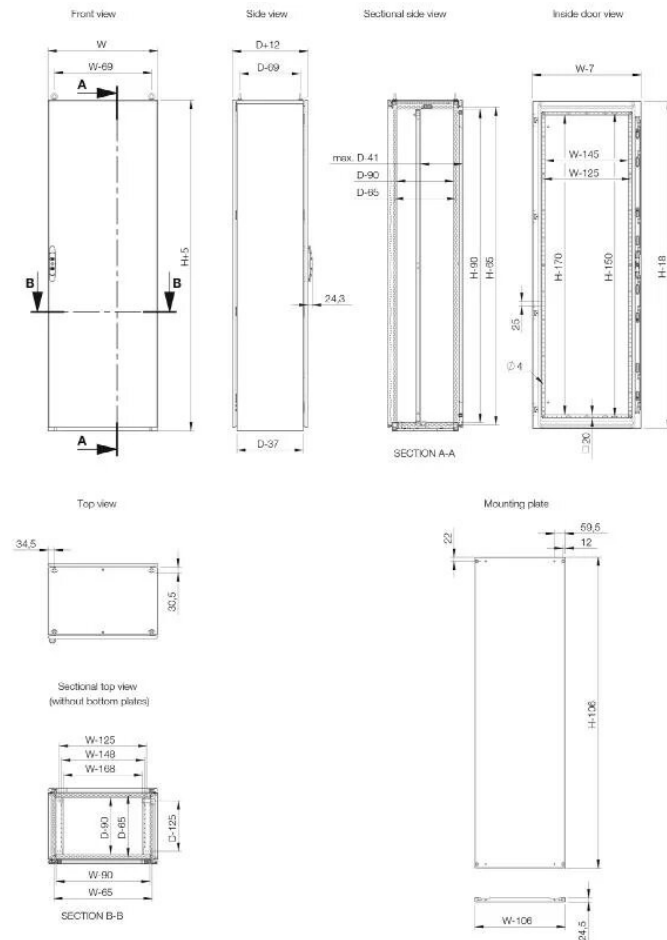

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE