

模块化单开门，MCSS



The stainless steel single door combinable floor standing enclosure range, MCSS, with a IP 55 protection degree, is available off the shelf in many different sizes. The risk for component failure, and with that unnecessary downtime, is eliminated as water and dust are prevented from entering the enclosure. This enclosure range is well suited for almost any environment, grade dependent.

工业标准

UL 508A; Type 12; 文件编号 E92044

cUL Listed per CSA C22.2 No.0, No.0.4, No.14, No.94; Type 12; File No. E92044

CSA, 文件编号 1442951) : Type 12

CSA, File No. 1442951: Type 12

IEC 62208 IP55

CE, UK CA, UL, DNV

功能

Levering inkluderer: Ramme med monterede døre, bagpanel, toppanel, bundplader, monteringsplade og dørørramme. Levering omfatter også bolte til jording. Leveres på palle i samme bredde som skabet, så skabene kan kombineres uden at fjerne dem fra pallerne. Alt emballeringsmateriale kan genbruges.}

Material: AISI 304L pre-grained stainless steel / AISI 316L. Frame: 1.5 mm. Door: 2 mm. Rear, roof and side panels: 1.5 mm. Bottom plates: 1.5 mm stainless steel. Mounting plate: 3 mm galvanized steel.

Frame: Seam welded reversed open profiles with 25 mm hole pattern, according to DIN 43660.

Door: Mounted with four hinges allowing left or right hand opening. Including door frame with 25 mm hole pattern.

Rear panel: Fitted by M6 torx screws. Standard facilities for rear door mounting.

Side panels: Supplied as an accessory.

Roof panel: Removable.

Lock: Espagnolette 4-point locking system. Does not interfere with the enclosure inner space. Standard double-bit 3 mm insert. Standard inserts, cylinders, lift handles and T-handle are available as accessories.

Bottom plates: One piece bottom plate, with injected polyurethane gasket to ensure maximum sealing.

Mounting plate: Double folded and slides into position. Adjustable in depth by steps of 25 mm, with the MPD02 accessory. Mounting plate is supplied, attached on the outside of the enclosure packaging.

Earthing: All panels are earthed through their fittings and are equipped with a separate earthing stud.

Finish: 400 pre-grained stainless steel.


Protection: Corresponds with IP 55 | TYPE 12 | IK 10.

Mounting requirements: Standard delivery ready for combined installation. For stand-alone installation, add side panels.

主体厚度: 1.5mm
门厚: 2mm
完成: 拉丝

技术参数

物料号	订货号	高度 (H)	宽度 (W)	深度 (D)	材料
MCSS20086	MCSS20086	2000mm	800mm	600mm	不锈钢
MCSS18065-316		1800mm	600mm	500mm	不锈钢 316
MCSS20106		2000mm	1000mm	600mm	不锈钢 304
MCSS18085	MCSS18085	1800mm	800mm	500mm	不锈钢
MCSS20086-316		2000mm	800mm	600mm	不锈钢 316
MCSS18085-316		1800mm	800mm	500mm	不锈钢 316
MCSS18105		1800mm	1000mm	500mm	不锈钢 304
MCSS18065	MCSS18065	1800mm	600mm	500mm	不锈钢
MCSS18105-316		1800mm	1000mm	500mm	不锈钢 316
MCSS20106-316		2000mm	1000mm	600mm	不锈钢 316
MCSS20066-316		2000mm	600mm	600mm	不锈钢 316
MCSS20066	MCSS20066	2000mm	600mm	600mm	不锈钢

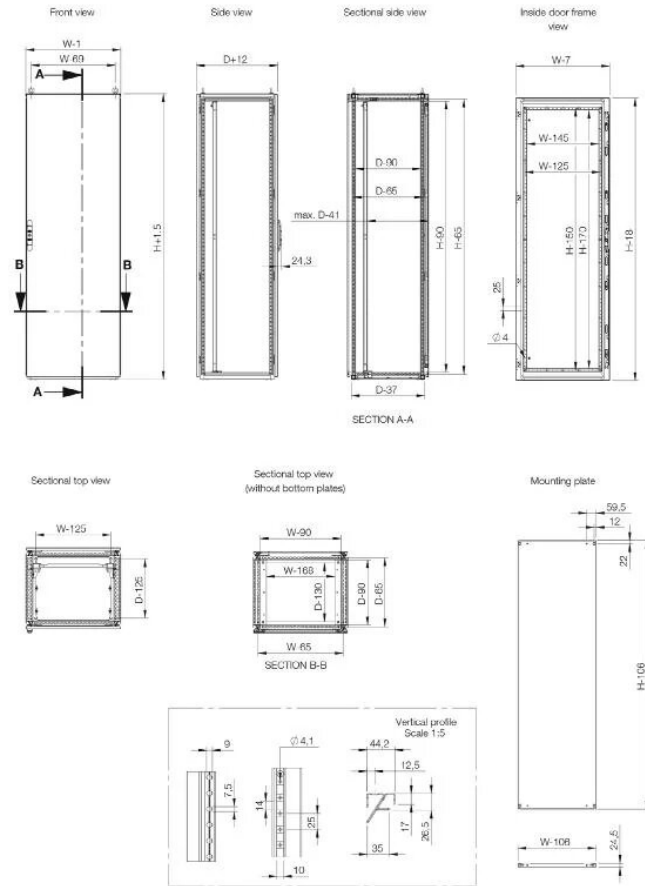

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

