

Oil And Gas Stainless Steel Single Door Enclosure, ASR-OG



The stainless steel single door wall mounted enclosure range, ASR-OG, with a IP 66 protection degree, is available off the shelf in four different sizes that accommodate majority of common applications. The risk for component failure, and with that unnecessary downtime is eliminated, as water and dust are prevented from entering the enclosure. This enclosure range is well suited for installation of industrial equipment in environments exposed to corrosive process chemicals, including chloride, marine applications subject to saltwater spray, and coastal areas.

工业标准

CE, UK CA

功能

Material: AISI 316L pre-grained stainless steel. Body: 2 mm. Door: 2 mm. Gland plate: 2 mm. Mounting plate: 2mm galvanized steel.

Body: Folded and seam welded with wall mounting brackets welded on the rear. Top of the body is equipped with integrated M12 blind nuts, enabling safe and easy handling using LE9316SS lifting eyes.

Door: Corner formed in one piece. Surface mounted, with 130° opening. Concealed AISI 316L stainless steel hinges with captive pin. Can be mounted to allow left or right hand opening. Sealing is ensured by an injected polyurethane gasket. For AISI 316L, sealing is ensured by an injected silicone gasket. Inner M6 welded studs, to mount optional door profiles MMDP.

Lock: With T-Handle lock with key 333 in Stainless Steel 316L, and espagnolette three point locking in Stainless Steel 316.

Mounting plate: The mounting plate is marked vertically at 10 mm intervals for easy horizontal positioning of equipment. On the top and bottom there are holes to facilitate cable fixing. Fixed onto M8 press welded studs to the rear of the enclosure. All sides from 800 mm and above are strengthened by folded edges. By using the AMG accessory the mounting plate position can be adjusted to any depth.

Cable access: With gland plate in the bottom to make cabling onto the mounting plate easier.

Protection: Corresponds with IP66 I TYPE 4x, 12 I IK 10.

Finish: 240s pre grained stainless steel (average 0,5 micron).

Approvals: CE, DNV-GL, GOST, Lloyd's Register, RS.

Delivery: Enclosure with door, mounting plate, gland plate and mounting accessories.


主体厚度: 2mm

门厚: 2mm

完成: 拉丝

技术参数

物料号	高度 (H)	宽度 (W)	深度 (D)	包含安装板	最大安装深度	材料
ASR0808030PEOG	800mm	800mm	300mm	否	282mm	不锈钢
ASR1208040OG	1200mm	800mm	400mm	是	382mm	不锈钢 316
ASR1208040PEOG	1200mm	800mm	400mm	否	382mm	不锈钢
ASR1208030PEOG	1200mm	800mm	300mm	否	282mm	不锈钢
ASR1208030OG	1200mm	800mm	300mm	是	282mm	不锈钢 316
ASR1008040PEOG	1000mm	800mm	400mm	否	382mm	不锈钢
ASR0808030OG	800mm	800mm	300mm	是	282mm	不锈钢 316
ASR1008040OG	1000mm	800mm	400mm	是	382mm	不锈钢 316

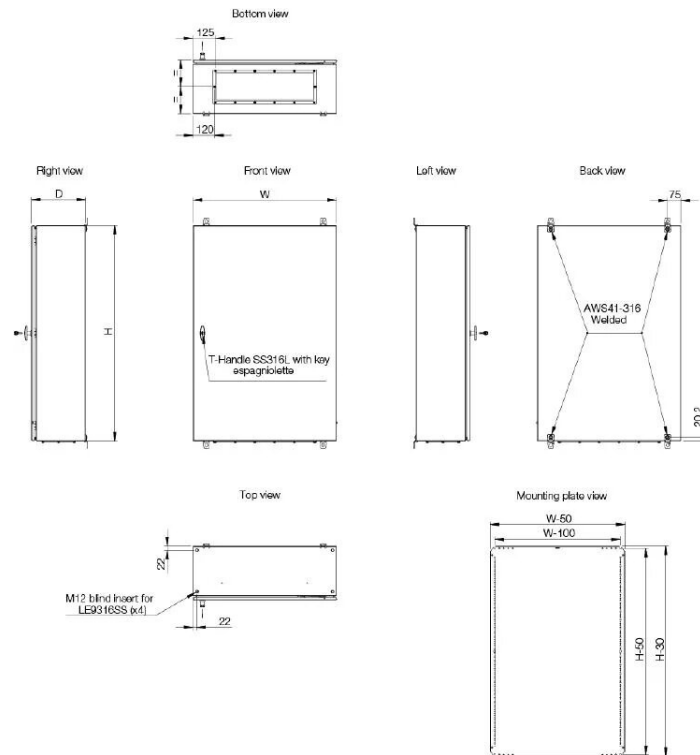

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE