


Polyester Compact Wall Mounted Enclosures, UCP/UCPT

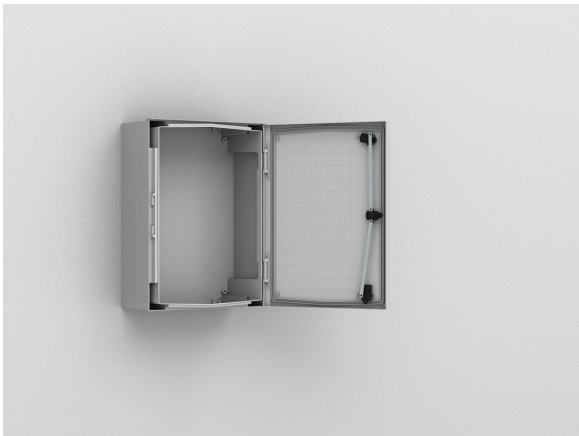

The polyester single door compact wall mounted enclosure range, UCP/UCPT, with a IP 66/IP 54 protection degree, is available off the shelf in many different sizes. Either a plain door or transparent door can be ordered. This enclosure range is well suited for outdoor installations, even when exposed to direct sunlight. The risk for component failure, and with that unnecessary downtime, is eliminated as water and dust are prevented from entering the enclosure.

工业标准

cULus_UL Listed

CE UKCA

GOST

功能

Material: Fibre-glass reinforced polyester. UCPT viewing area: polycarbonate.

Body: Monoblock moulded 3 mm thick. Four holes for direct wall fixing. Without gland plate openings.

Door: Door, with or without window and 180° opening. For UCP/UCPT750 and above, a door support is supplied for easier closing. Sealing is by an injected one piece polyurethane gasket.

Lock: Double-bit 3 mm insert and 90° movement. UCP/UCPT540 and above have three locking points. Other locks are available as an accessory.

Temperature resistance: -25 °C to 70 °C in continuous use (peak temperatures up to 130 °C).

Characteristics: Self extinguishing and halogen free. Double insulated, according to EN61439-1. Rated insulation voltage $U_i = 1000 \text{ V ac}$ and 1500 V dc .

Protection: IP 66, TYPE 4, 4X, 12, 13 for UCP (except UCP320 and UCP430, which are rated IP65). IP54 TYPE 12 for UCPT. Impact resistance IK 08 (IK 07 for cabinets with transparent doors UCPT).

Approvals: CE, GOST. CSA and cULus_UL Listed approvals apply to plain door enclosures only. For further approvals, please contact nVent HOFFMAN's sales department.

Finish: RAL 7035, precoloured raw material.


Delivery: Enclosure with door, fixing screws for the mounting plate and a self adhesive rain strip.

Note: UCP320, UCP430 and UCP540 are delivered with the doors inside the packaging, unmounted.

主体厚度: 3mm
颜色: 浅灰色
材料: 聚酯
颜色代码: RAL 7035
完成: 平滑

技术参数

物料号	高度 (H)	宽度 (W)	深度 (D)	门类型	门锁数量	重量
UCPT860	835mm	635mm	300mm	透明	3	15kg
UCP430	415mm	315mm	170mm	普通	1	3.9kg
UCP540	515mm	415mm	230mm	普通	3	6.9kg
UCPT750	735mm	535mm	270mm	透明	3	11.8kg
UCP640	615mm	415mm	230mm	普通	3	7kg
UCP320	315mm	215mm	170mm	普通	1	2.8kg
UCP750	735mm	535mm	270mm	普通	3	11.7kg
UCPT640	615mm	415mm	230mm	透明	3	7.3kg
UCP860	835mm	635mm	300mm	普通	3	14.9kg
UCPT540	515mm	415mm	230mm	透明	3	7.1kg
UCPT1080	1035mm	835mm	300mm	透明	3	22.3kg
UCP1080	1035mm	835mm	300mm	普通	3	22.8kg
UCPT430	415mm	315mm	170mm	透明	1	3.9kg

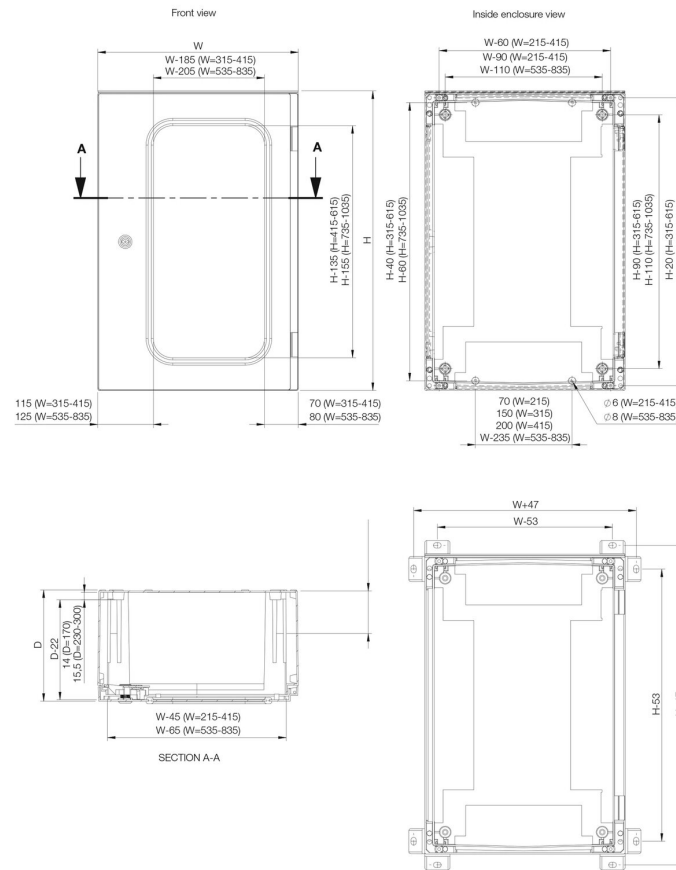

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE