


Polyester Modular Single Door Enclosures, UDP/UDPT

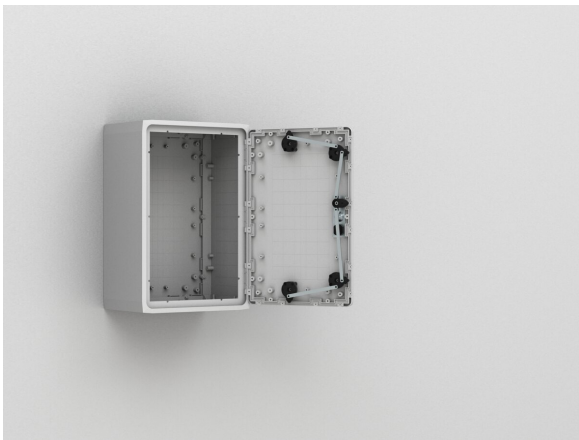

The polyester modular wall mounted enclosure range, UDP/UDPT, with a IP 65/54 protection degree, is available off the shelf in many different sizes. Either a plain door or transparent door can be ordered. Several enclosures may be combined to extend the width or depth to, for example, accommodate large components and maintain internal communication. This enclosure range is well suited for outdoor installations, even when exposed to direct sunlight. The risk for component failure, and with that unnecessary downtime, is eliminated as water and dust are prevented from entering the enclosure.

工业标准

cULus_UL Listed

GOST

CE UKCA

功能

Material: Fibre-glass reinforced polyester. UDPT viewing area: polycarbonate.

Body: Modular moulded, with rear fixing. Direct fixing to the wall or by use of wall mounted brackets. To a pole by use of EPF, to the floor by use of the plinth UPP or DIN-base UAF and UMPS. In single plain door enclosures, sealing is ensured by an EPDM gasket glued against the frame.

Door: Flush mounted door, with or without window and 100° opening. For larger sizes, a door support is supplied for easier closing. For window doors sealing is ensured by a polyurethane gasket.

Lock: Premounted handle, suitable for all types of half cylinder locks (standard depth of 40 mm). Five locking points (three points in 500 mm width enclosures).

Temperature resistance: -25 °C to 70 °C in continuous use (peak temperatures up to 130 °C).

Characteristics: Self extinguishing and halogen free. Double insulated, according to EN61439-1. Rated insulation voltage U_i = 1000 V ac and 1500 V dc.

Protection: Complies with IP 65, TYPE 4, 4X, 12, 13 for single plain door enclosures. IP 54, TYPE 3, 3R, 3S for transparent door enclosures. Impact resistance IK 10. IK 07 for enclosures with transparent door.

Approvals: CE, CSA, GOST. cULus_UL Listed for single door enclosures. For further approvals, please contact nVent HOFFMAN's sales department.


Finish: RAL 7035, precoloured raw material.

Delivery: Enclosure with door, fixing screws for the mounting plate and wall mounting brackets. (Lock cylinder is not included in the delivery).

颜色: 浅灰色
材料: 聚酯; 聚碳酸酯
颜色代码: RAL 7035
完成: 平滑

技术参数

物料号	高度 (H)	宽度 (W)	深度 (D)	门类型	门数量	重量
UDP10075	1000mm	750mm	320mm	普通	1	29kg
UDPT7550	750mm	500mm	320mm	透明	1	18kg
UDP12575	1250mm	750mm	320mm	普通	1	32kg
UDP10050	1000mm	500mm	320mm	普通	1	22.3kg
UDPT10050	1000mm	500mm	320mm	透明	1	22.1kg
UDP7550	750mm	500mm	320mm	普通	1	18kg
UDPT5050	500mm	500mm	320mm	透明	1	14.6kg
UDPT10075	1000mm	750mm	320mm	透明	1	27.3kg
UDP75100	750mm	1000mm	320mm	普通	1	28kg
UDP5050	500mm	500mm	320mm	普通	1	14.4kg
UDP100100	1000mm	1000mm	320mm	普通	1	34.2kg
UDPT7575	750mm	750mm	320mm	透明	1	31.9kg
UDP7575	750mm	750mm	320mm	普通	1	24kg
UDPT5075	500mm	750mm	320mm	透明	1	14.8kg
UDPT12575	1250mm	750mm	320mm	透明	1	31.9kg
UDP5075	500mm	750mm	320mm	普通	1	18.2kg

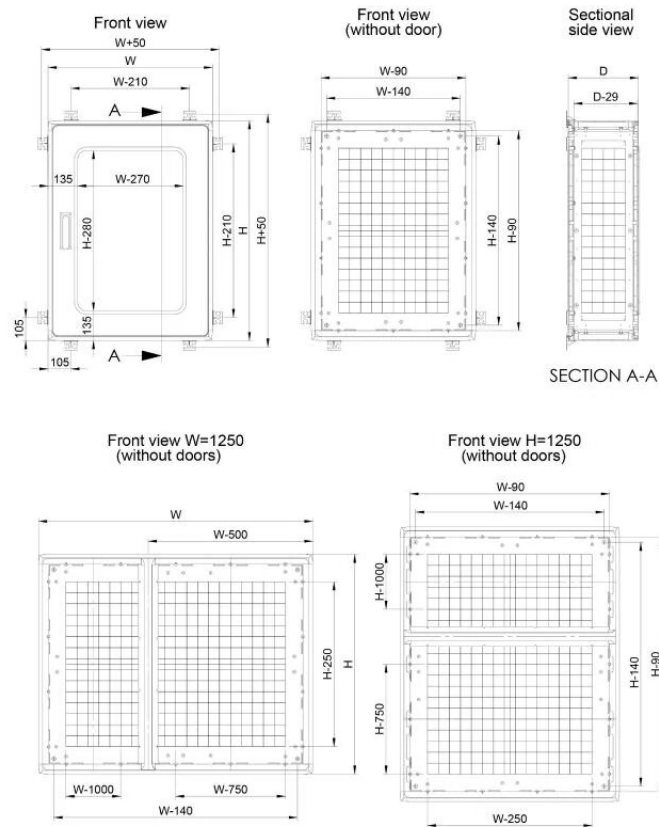

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE