


Roof Fan Unit, RFU

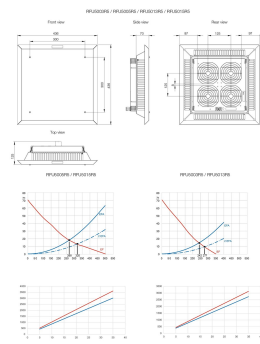

This roof filter fan, RFU, with either a IP 33 or 54 protection degree, to be mounted on the enclosure's roof, is easily mounted with a click-in feature. Thus, no surface needs to be used on the door. Component failure and downtime is eliminated as water and dust are prevented from entering the enclosure. The filter fan's reliable motor guarantees constant ventilation within each enclosure on which the fan is installed.

工业标准

UL 508A Component Recognized

CE

UKCA

EAC

功能

Description: Roof fan unit for mounting on the top of the enclosure providing forced ventilation. The unit is easily installed with a quick fastening system, and the required cutout is the same for the different air flow.

Material: Painted mild steel, and injection-moulded thermoplastic (ABS-FR) self extinguishing, UL94V0.

Temperature range: -15 °C to +55 °C.

Type of connection: Terminal strip.

Finish: RAL 7035.

Pack quantity: One roof fan unit.

Roof fan unit for mounting on the top of the enclosure providing forced ventilation

The unit is easily installed with a quick fastening system, and the required cutout is the same for the different air flow

Temperature range: -15 °C to +55 °C

Bearing Type: Ball

Protection: IP33 No filtermat; IP54 Filtermat

颜色: 浅灰色

材料: 低碳钢
完成: 粉末涂层
颜色代码: RAL 7035

技术参数

物料号	自由气流	高度	宽度	深度	开孔尺寸	标称电压
RFU5015R5	350*m³/h	125mm	436mm	436mm	291 x 291mm	115V
RFU5003R5	500*m³/h	125mm	436mm	436mm	291 x 291mm	230V
RFU5005R5	350*m³/h	125mm	436mm	436mm	291 x 291mm	230V
RFU5013R5	500*m³/h	125mm	436mm	436mm	291 x 291mm	115V
RFU10003R5	1000*m³/h	148mm	470mm	470mm	291 x 291mm	230V
RFU10015R5	750*m³/h	148mm	470mm	470mm	291 x 291mm	115V
RFU7005R5	550*m³/h	148mm	470mm	470mm	291 x 291mm	230V
RFU7013R5	700*m³/h	148mm	470mm	470mm	291 x 291mm	115V
RFU10013R5	1000*m³/h	148mm	470mm	470mm	291 x 291mm	115V
RFU7003R5	700*m³/h	148mm	470mm	470mm	291 x 291mm	230V
RFU7015R5	550*m³/h	148mm	470mm	470mm	291 x 291mm	115V
RFU10005R5	750*m³/h	148mm	470mm	470mm	291 x 291mm	230V
RFUM0710					291 x 291mm	
RFUM05					291 x 291mm	

其他产品详情

(1) The value in the table is for the combination RFU + EFA500-700R5.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

⚠ WARNING: This product can expose you to chemicals including styrene, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE