


Simple Protection Cables Entry For Wall Mounted Enclosures, CES

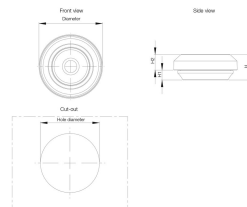

The rubber cable gland is easy to mount, and cables and pipes can be pulled through at an angle easily without tools, ensuring that the enclosure's protection degree is maintained.

功能

Description: Simple grommet manufactured in a rubber-like material. The installation does not require tools. The “pushout” membrane is a permanent seal until it is penetrated by a cable or pipe. It is equipped with a sock that closes tight around the cable and allows for it to be moved around like a “joy-stick” in the opening without endangering the IP, so it works extremely well with cables passing through at an angle. Suitable for holes in materials of 0.5 to 4.5 mm thickness.

Material: TPE (thermoplastic elastomer), halogen free.

Temperature resistance: -50 °C to +125 °C.

Finish: RAL 7035.

Protection: IP 67.

The installation does not require tools

The “pushout” membrane is a permanent seal until it is penetrated by a cable or pipe

It is equipped with a sock that closes tight around the cable and allows for it to be moved around like a “joy-stick” in the opening without endangering the IP, so it works extremely well with cables passing through at an angle


Suitable for holes in materials of 0.5 to 4.5 mm thickness

颜色: 浅灰色
颜色代码: RAL 7035
完成: 平滑
材料: 热塑性合成橡胶

技术参数

物料号	高度 (H)	宽度 (W)	深度 (D)	高度 (H)	直径	电缆直径范围
CES16	11mm	24mm	24mm	4mm min	23.5mm	5 – 10mm
CES25	11mm	33mm	33mm	4mm min	39.5mm	8 – 17mm
CES20	11mm	28mm	28mm	4mm min	27.5mm	6 – 13mm
CES32	11mm	40mm	40mm	4mm min	39.5mm	12 – 24mm

图

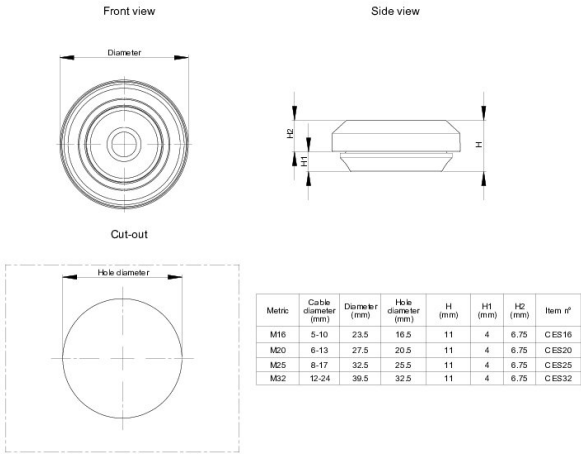

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合：
CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE