

接线盒，低碳钢，STB



The mild steel terminal box range, STB, with a IP 66 protection degree, is available off the shelf in many different sizes. The STB range is well suited for demanding indoor environments. Water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that, unnecessary downtime.

工业标准

UL 508A; Type 4, 12, 13; 文件编号 E92044

cUL Listed per CSA C22.2 No.0, No.0.4, No.14, No.94; Type 4 12, 13; File No. E92044

NEMA/EEMAC Type 4, 12, 13

IEC 62208 IP66

CE, UK CA, UL

功能

Material: 1.2 mm mild steel.

Body: Folded and seam welded. Four 8.5 mm diameter holes for wall fixing. Four M6 × 13 studs for bottom profiles / mounting plate fixation.

Gasket: Sealing is ensured by an injected one piece polyurethane gasket.

Earthing: M8x18 mm earthing studs in body and cover, M8 nuts, earthing washers and earthing labels.

Protection: IP 66, TYPE 4, 12, IK 08.

Finish: RAL 7035, structured powder coating.

Delivery: Body, cover, cover screws, fixing screws, cover plugs, and earthing facilities.

主体厚度:	1.2mm
门厚:	1.2mm
颜色:	浅灰色
材料:	低碳钢
完成:	粉末涂层
颜色代码:	RAL 7035


技术参数

Table 1/2					
物料号	订货号	高度 (H)	宽度 (W)	深度 (D)	重量
STB151508	STB151508	150mm	150mm	80mm	1.2kg
STB205012	STB205012	200mm	500mm	120mm	4.3kg
STB406012	STB406012	400mm	600mm	120mm	8.2kg
STB203008	STB203008	200mm	300mm	80mm	2.4kg
STB305012	STB305012	300mm	500mm	120mm	5.7kg
STB303008	STB303008	300mm	300mm	80mm	3.3kg
STB151512	STB151512	150mm	150mm	120mm	1.4kg
STB153008	STB153008	150mm	300mm	80mm	2kg
STB206012	STB206012	200mm	600mm	120mm	5kg
STB303012	STB303012	300mm	300mm	120mm	3.7kg
STB202012	STB202012	200mm	200mm	120mm	2.1kg
STB204008	STB204008	200mm	400mm	80mm	3kg
STB203012	STB203012	200mm	300mm	120mm	2.9kg
STB404012	STB404012	400mm	400mm	120mm	6.1kg
STB202008	STB202008	200mm	200mm	80mm	1.8kg
STB306012	STB306012	300mm	600mm	120mm	6.7kg
STB208012	STB208012	200mm	800mm	120mm	6.6kg
STB408012	STB408012	400mm	800mm	120mm	10.5kg
STB304012	STB304012	300mm	400mm	120mm	4.7kg
STB204012	STB204012	200mm	400mm	120mm	3.5kg

Table 2/2					
物料号	订货号	高度 (H)	宽度 (W)	深度 (D)	重量
STB153012	STB153012	150mm	300mm	120mm	2.3kg

其他产品详情

Panel sold separately.

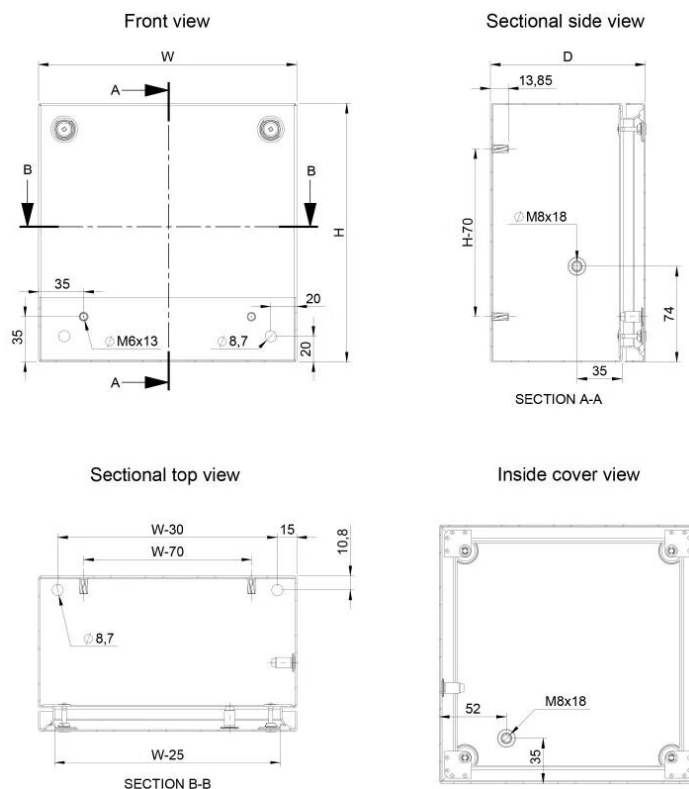

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE