

接线盒，不锈钢，SSTB



The stainless steel terminal box range, SSTB, with a IP 66 protection degree, is available off the shelf in many different sizes. The SSTB range is well suited for indoor and outdoor environments thanks to its corrosion resistance. Water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that, unnecessary downtime.

工业标准

UL 508A Listed; Type 4X, 12, 13; File No. E92044
cUL Listed per CSA C22.2 No.0, No.0.4, No.14, No.94;
Type 4X 12, 13; File No. E92044

NEMA/EEMAC 4X、12、13 型

IEC 62208 IP66

CE, UK CA, UL

功能

Material: AISI 304L pre-grained stainless steel / AISI 316L (on request). Body: 1 mm. Cover: 1.5 mm.

Body: Folded and seam welded. Four M6x13 studs for bottom profile / mounting plate fixation. For ease of installation, each back corner of the enclosure is laser-marked to precisely indicate where to drill holes and affix AWS wall mounting brackets.

Gasket: Sealing is ensured by an injected polyurethane gasket or by an injected silicone gasket.

Earthing: M8x18 mm earthing studs in body and cover, M8 nuts, earthing washers and earthing labels.

Protection: IP 66 | TYPE 4X, 12 | IK 08.

Finish: 400 pre-grained stainless steel.

Delivery: Body, cover, cover screws, fixing screws, cover plugs and earthing facilities.

主体厚度: 1mm
门厚: 1.5mm
完成: 拉丝

技术参数

Table 1/3						
物料号	订货号	高度 (H)	宽度 (W)	深度 (D)	垫片类型	材料
SSTB305012-316	SSTB305012-316	300mm	500mm	120mm	硅树脂	不锈钢 316
SSTB204012-316	SSTB204012-316	200mm	400mm	120mm	硅树脂	不锈钢 316
SSTB205012	SSTB205012	200mm	500mm	120mm	聚氨酯	不锈钢 304
SSTB202008-316	SSTB202008-316	200mm	200mm	80mm	硅树脂	不锈钢 316
SSTB404012	SSTB404012	400mm	400mm	120mm	聚氨酯	不锈钢 304
SSTB205012-316	SSTB205012-316	200mm	500mm	120mm	硅树脂	不锈钢 316
SSTB306012-316	SSTB306012-316	300mm	600mm	120mm	硅树脂	不锈钢 316
SSTB151512	SSTB151512	150mm	150mm	120mm	聚氨酯	不锈钢 304
SSTB206012	SSTB206012	200mm	600mm	120mm	聚氨酯	不锈钢 304
SSTB202008	SSTB202008	200mm	200mm	80mm	聚氨酯	不锈钢 304
SSTB206012-316	SSTB206012-316	200mm	600mm	120mm	硅树脂	不锈钢 316
SSTB306012	SSTB306012	300mm	600mm	120mm	聚氨酯	不锈钢 304
SSTB208012	SSTB208012	200mm	800mm	120mm	聚氨酯	不锈钢 304
SSTB153012-316	SSTB153012-316	150mm	300mm	120mm	硅树脂	不锈钢 316
SSTB203008-316	SSTB203008-316	200mm	300mm	80mm	硅树脂	不锈钢 316
SSTB151512-316	SSTB151512-316	150mm	150mm	120mm	硅树脂	不锈钢 316
SSTB208012-316	SSTB208012-316	200mm	800mm	120mm	硅树脂	不锈钢 316
SSTB303008	SSTB303008	300mm	300mm	80mm	聚氨酯	不锈钢 304
SSTB153012	SSTB153012	150mm	300mm	120mm	聚氨酯	不锈钢 304
SSTB305012	SSTB305012	300mm	500mm	120mm	聚氨酯	不锈钢 304


Table 2/3						
物料号	订货号	高度 (H)	宽度 (W)	深度 (D)	垫片类型	材料
SSTB303008-316	SSTB303008-316	300mm	300mm	80mm	硅树脂	不锈钢 316
SSTB303012	SSTB303012	300mm	300mm	120mm	聚氨酯	不锈钢 304
SSTB304012-316	SSTB304012-316	300mm	400mm	120mm	硅树脂	不锈钢 316
SSTB153008	SSTB153008	150mm	300mm	80mm	聚氨酯	不锈钢 304
SSTB153008-316	SSTB153008-316	150mm	300mm	80mm	硅树脂	不锈钢 316
SSTB303012-316	SSTB303012-316	300mm	300mm	120mm	硅树脂	不锈钢 316
SSTB304012	SSTB304012	300mm	400mm	120mm	聚氨酯	不锈钢 304

物料号	订货号	高度 (H)	宽度 (W)	深度 (D)	垫片类型	材料
SSTB203012	SSTB203012	200mm	300mm	120mm	聚氨酯	不锈钢 304
SSTB203012-316	SSTB203012-316	200mm	300mm	120mm	硅树脂	不锈钢 316
SSTB151508	SSTB151508	150mm	150mm	80mm	聚氨酯	不锈钢 304
SSTB406012-316	SSTB406012-316	400mm	600mm	120mm	硅树脂	不锈钢 316
SSTB204008	SSTB204008	200mm	400mm	80mm	聚氨酯	不锈钢 304
SSTB202012-316	SSTB202012-316	200mm	200mm	120mm	硅树脂	不锈钢 316
SSTB408012	SSTB408012	400mm	800mm	120mm	聚氨酯	不锈钢 304
SSTB203008	SSTB203008	200mm	300mm	80mm	聚氨酯	不锈钢 304
SSTB204008-316	SSTB204008-316	200mm	400mm	80mm	硅树脂	不锈钢 316
SSTB406012	SSTB406012	400mm	600mm	120mm	聚氨酯	不锈钢 304
SSTB204012	SSTB204012	200mm	400mm	120mm	聚氨酯	不锈钢 304
SSTB202012	SSTB202012	200mm	200mm	120mm	聚氨酯	不锈钢 304
SSTB151508-316	SSTB151508-316	150mm	150mm	80mm	硅树脂	不锈钢 316

Table 3/3

物料号	订货号	高度 (H)	宽度 (W)	深度 (D)	垫片类型	材料
SSTB404012-316	SSTB404012-316	400mm	400mm	120mm	硅树脂	不锈钢 316
SSTB408012-316	SSTB408012-316	400mm	800mm	120mm	硅树脂	不锈钢 316

图

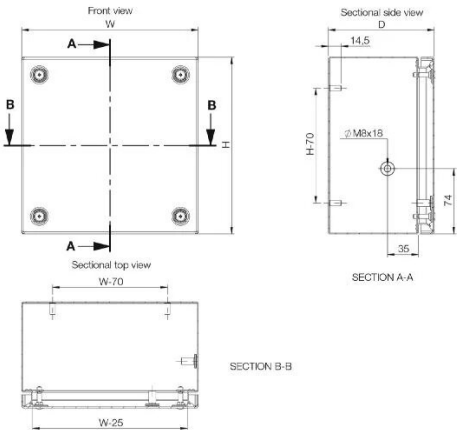

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE