

HFF Steel Nailing Plate



The HFF nailing plate is sold separately from the A12 couplers. The plates easily attach to the couplers by orienting the hexagon opening in the plate to the coupler and then rotating the plate 15 degrees.

Used in segmental pour and closure pour applications. Permanent form saving plates allow easy attachment to form work, eliminating costly damage to the forms.

功能

Designed for use with the A12 coupler families

Positively locks onto the hexagon-shaped coupler

Easy to install

No special tools required

材料: 弹簧钢

技术参数

Table 1/2

物料号	订货号	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	长度 (L)	六角宽度 (W)
EL1820HFF	152860	18 mm, 20 mm	#6	20M	50mm	27 mm
EL2225HFF	154420	22 mm, 25 mm	#7, #8	25M	70mm	36 mm
EL1012HFF	152840	10 mm, 12 mm	#3, #4	10M	50mm	17 mm
EL1416HFF	152850	14 mm, 16 mm	#5	15M	50mm	22 mm

Table 2/2

物料号	订货号	高度 (H)	包装数量
EL1820HFF	152860	5 mm	100
EL2225HFF	154420	5 mm	75
EL1012HFF	152840	5 mm	100


物料号	订货号	高度 (H)	包装数量
EL1416HFF	152850	5 mm	100

其他产品详情

Can also be used on A2N couplers.

Always wear gloves when installing plates to couplers.

图

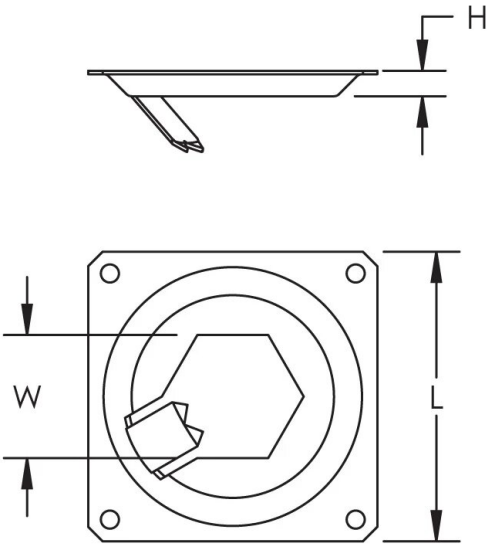

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE